




ENGLISH

Datasheet


**Stock No: 144-1610**

**RS Pro Socket**

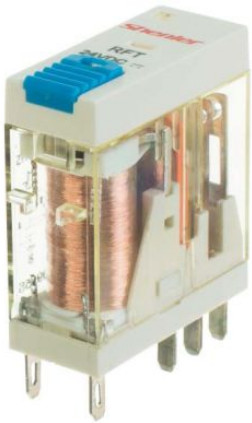

# Specifications:

**ENGLISH**

<b>RS Stock No</b>		<b>144-1610</b>
<b>Characteristics</b>		
Nominal Load	Current	16A
	Voltage	300V
Dielectric Strength	Between Coil and Contact	4000 V/S
	Between Contacts	2500 V/S
Max. Tightening Torque		1.0 Nm
Wire Size		20-14 AWG / 0.5-2.5mm <sup>2</sup>
Ambient Temperature		-45-+85°C
Unit Weight		22G
Certification		
<b>Dimensions</b>		<b>Connection Diagram</b>
