


## FEATURES

- **Non-Releasable Design:** Ensures a secure hold that prevents accidental release, maintaining cable organisation.
- **UV Resistant:** Suitable for outdoor use, resisting degradation from sunlight exposure.
- **High Tensile Strength of 18 kg:** Provides strong and reliable support for bundled cables.
- **Wide Temperature Range:** Operates effectively from -40 °C to 85 °C, suitable for diverse environments.
- **RoHS Compliant:** Meets environmental and safety standards, ensuring safe use.
- **UL 94HB Rated:** Offers a level of flame retardancy for added safety.

## RS PRO Nylon Cable Tie, 292mm Non-Releasable

RS Stock No: 656-096

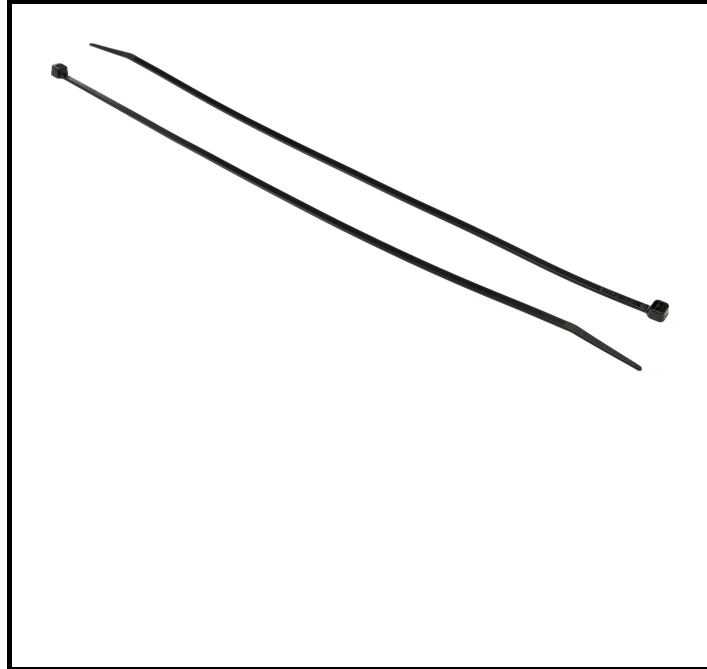

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

### Product Description

These RS PRO nylon cable ties are designed for secure and reliable bundling of cables and wires. Ideal for use in various industrial and commercial settings, they provide a robust solution for organising and managing cable installations. With a high tensile strength, these cable ties ensure durability and long-term performance.

### General Specifications

Colour	Black
Product Type	Cable Tie
Sub Type	Non-Releasable
Tensile Strength	18 kg

### Protection Category

Fire Behaviour	UL 94HB
UV Resistant	Yes

### Mechanical Specifications

Length	292 mm
Material	Nylon
Maximum Bundle Diameter	82 mm
Width	3.6 mm

### Operation Environment Specifications

Maximum Operating Temperature	85 °C
Minimum Operating Temperature	-40 °C

### Approvals

Standards/Approvals	RoHS, UL94HB
---------------------	--------------

