

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0151310400](#)
Status: **Active**
Overview: [Pico-Lock Connector System](#)
Description: Pico-Lock-to-Pico-Lock Off-the-Shelf (OTS) Cable Assembly, 1.00mm Pitch, Single Row, 50.00mm Length, 4 Circuits, Black

Documents:

[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	15131
Assembly Configuration	Dual Ended Connectors
Connector to Connector	Pico-Lock-to-Pico-Lock
Overview	Pico-Lock Connector System
Product Literature Order No	987651-6143
Product Name	Pico-Lock OTS
UPC	191128284752

Physical

Cable Length	50.00mm
Circuits (Loaded)	4
Color - Resin	Black
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	0.484/g
Pitch - Mating Interface	1.00mm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	0.60mm
Wire Size AWG	28
Wire/Cable Type	UL 1571


Electrical

Voltage - Maximum	150V
-------------------	------

Material Info

Reference - Drawing Numbers

Sales Drawing	151310400-000
---------------	---------------

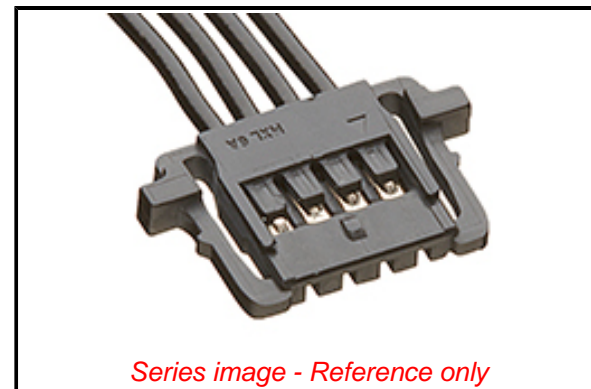

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/30/2017 (7 July
2017)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[15131](#) Series

Mates With

[503763](#) Pico-Lock Wire-to-Board Header