



fitted with

work equipment
connected load
power consumption
luminous flux
luminous efficacy
light distribution
light colour
color rendering index (CRI)
glare-free
system of protection
class of protection
technology
usage
luminaire body
lamp cover
tubular sections
balance of articulation joints
weight (net)
mains lead

fastening

special features

LED


Energy efficiency category A+
electronic ballast in housing
100-240 V; 50/60 Hz
approx. 9.5 W
approx. 600 lm
approx. 63 lm/W
direct, wide-angled beam
neutral white, approx. 5000 K
> 80
screen
IP 65 (67)
I
switchable, continuously dimmable
push button
aluminium, anodised, black
glass screen
flexible metal tube, black
friction
approx. 1.9 kg
approx. 3,2 m; mains plug
CEE 7/VII
screw-down flange, table clamp (accessory), wall bracket (accessory)
Flood with 40° angle of radiation



CEE 7/VII

illuminance

distance: 50 cm
Em: 3255 lx
Emax: 5600 lx
Emin: 1138 lx

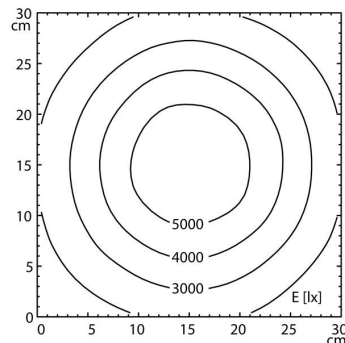

luminous intensity

