

# Signal lamp with integrated filament lamp, 10 mm, round bezel, 28 Volt, bezel yellow, Flat quick-connect terminal 2.8 x 0.8 tin-plated



## fields of application

- Measurement-control-regulation
- Electrical engineering
- Mechanical and system engineering
- Signalling systems
- Model construction

## special features

- Three shapes: round, square or arrow-shaped
- Integrated luminous element
- Filament lamp, 28 V, color: yellow
- Neon lamp, 230 V, color: red
- Luminous element neon lamp, 230 V, color: green or blue



## description

Signal lamps with integrated filament lamp, neon lamp or luminous element neon lamp, mounting hole diameter 10 mm

## technical data

### ➤ general

|                                                             |             |
|-------------------------------------------------------------|-------------|
| Bezel color                                                 | yellow      |
| Property of bezel / mushroom                                | transparent |
| Bezel shape                                                 | round       |
| illuminated                                                 | Yes         |
| Packaging unit                                              | 10 pcs.     |
| net weight                                                  | 2.1 g       |
| Degree of protection, front side, according to DIN EN 60529 | IP40        |
| MOQ order                                                   | 50 pcs.     |
| RoHS compliant                                              | Yes         |
| REACH compliant                                             | Yes         |

### direct links

➤ [RAFI eCatalog](#)

### ➤ mounting diameters

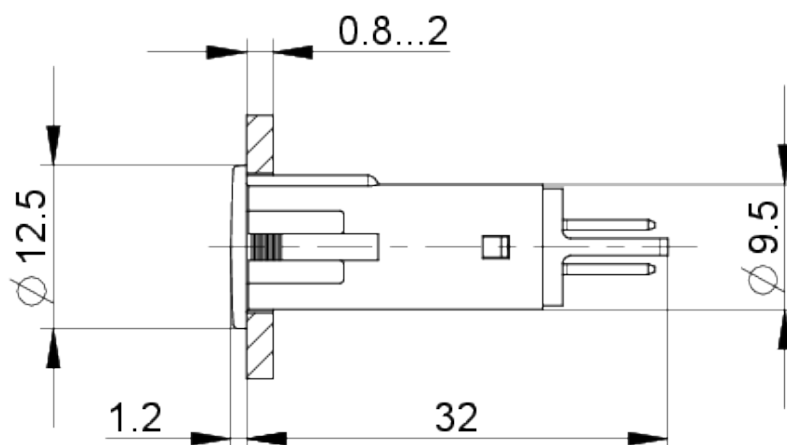
|                     |         |
|---------------------|---------|
| Mounting hole       | 10 mm   |
| Mounting depth      | 30 mm   |
| Installation height | 3 mm    |
| Collar dimension    | 12.5 mm |

### ➤ mechanical data

|                      |                                                  |
|----------------------|--------------------------------------------------|
| Fixing               | Pushing into mounting hole                       |
| Solderability        | Yes                                              |
| Terminal on the rear | Flat quick-connect terminal 2.8 x 0.8 tin-plated |

### ➤ electrical data

|                                                 |      |
|-------------------------------------------------|------|
| Operating voltage of the luminous element, max. | 28 V |
|-------------------------------------------------|------|

**drawings****Dimensioned drawing****Mounting hole drawing**