

640255-1 ✓ ACTIVE

SL-156


TE Internal #: 640255-1

Keying Plug, Natural, Nylon 6/6, SL-156

[View on TE.com >](#)



Connectors > Connector Accessories > Connector Hardware

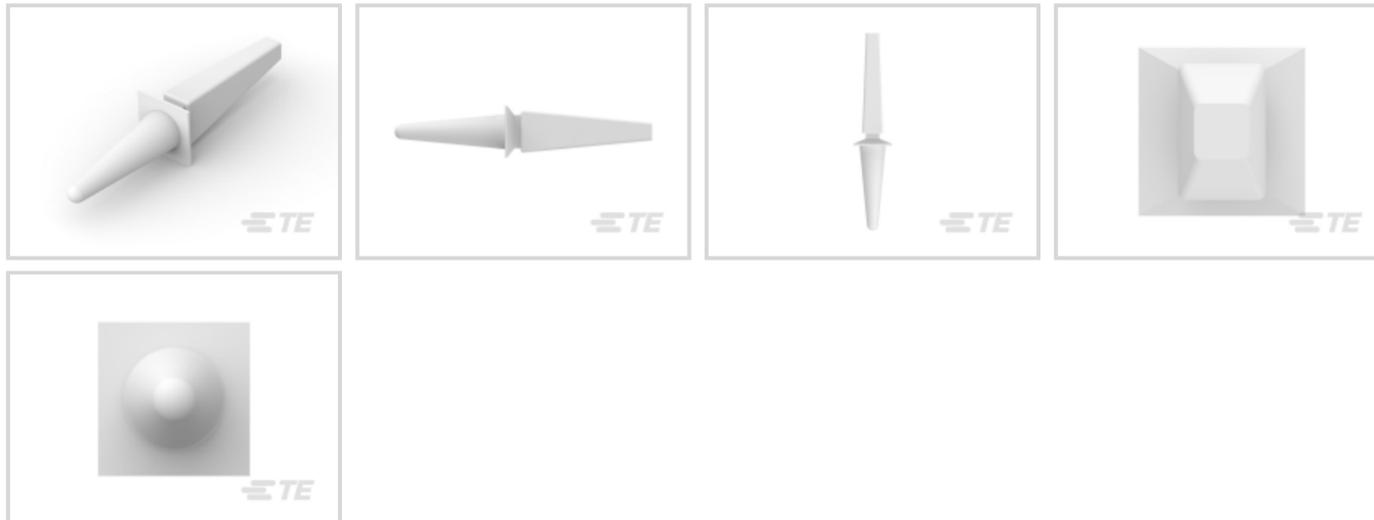

Hardware Accessory Function: **Coding & Keying**

Connector Hardware Accessory Type: **Keying Plug**

Primary Product Color: **Natural**

Primary Product Material: **Nylon 6/6**

Operating Temperature (Max): **105 °C [221 °F]**

Features

Product Type Features

Hardware Accessory Function	Coding & Keying
Connector Hardware Accessory Type	Keying Plug

Body Features

Primary Product Color	Natural
Primary Product Material	Nylon 6/6

Usage Conditions

Operating Temperature (Max)	105 °C[221 °F]
Operating Temperature Range	-55 – 105 °C[-67 – 221 °F]

Industry Standards

UL Flammability Rating	UL 94V-2
------------------------	----------

Packaging Features

Packaging Method	Bag
Packaging Quantity	2500

Product Compliance



For compliance documentation, visit the product page on [TE.com](https://www.te.com)>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

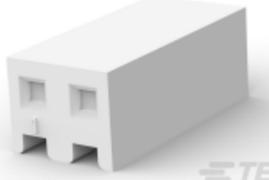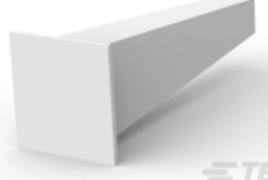 <p>TE Part # 3-770849-2 02P SL156 HSG W/LCK RMP & TABS BLACK</p>	 <p>TE Part # CAT-103156-RECHS Connector Housing, Rectangular, 3.96 mm, 1 Row</p>	 <p>TE Part # 640254-1 KEYING PLUG .045 SQ PST CONN</p>	 <p>TE Part # CAT-103156-WBHSM Receptacle Housing: Wire-to-Board, with Mating Alignment, SL156</p>
 <p>TE Part # 5-770849-2 02P SL156 HSG W/LCK RMP & TABS RED</p>	 <p>TE Part # 2327576-1 06P SL156 HSG NO3P THRU BD LTH UL94V0</p>	 <p>TE Part # 2-2132074-0 20Pos SL156 Contact Retainer</p>	

Also in the Series | SL-156



Connector Contacts(23)



Connector Hardware(4)



Power Contacts(13)



Rectangular Connector Housings(150)



Rectangular Power Connectors(147)



Standard Rectangular Connectors(150)



Wire-to-Board Connector Assemblies & Housings(146)

Customers Also Bought



TE Part #800309-SF
FN394-6-05-11



TE Part #1-66103-7
III+ PIN,24-20, 30AU/SN,SMPACK




TE Part #1-66105-8
III+ SKT,24-20,30AU/FL,SMPACK



TE Part #206060-1
CPC PLUG ASSEMBLY SIZE 11-4




TE Part #206903-2
SEALING CAP ASSY,SZ 11,CPC

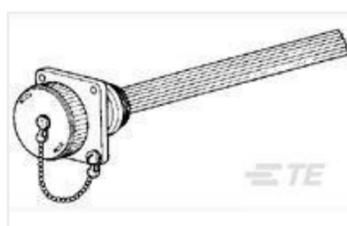

TE Part #207445-3
SEALING CAP ASSY, 17,CPC ROHS
Compliant



TE Part #211769-1
17-9 CPC RECEPT REV SEX

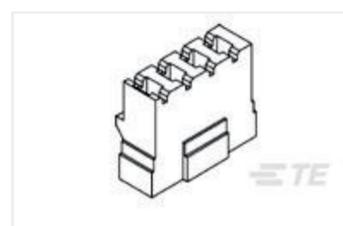

TE Part #1609140-3
PA105 J0=F6806



TE Part #1-1625984-0
HSA50 150R 5%



TE Part #4-6609929-2
PE0S0DHXB=C2256



Documents

Product Drawings

[KEYING PIN .045 SQ PST CONN](#)

English

CAD Files

[3D PDF](#)

3D

Customer View Model

[ENG_CVM_CVM_640255-1_J_c-640255-1-j.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_640255-1_J_c-640255-1-j.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_640255-1_J_c-640255-1-j.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

[Application Specification](#)

English

[Application Specification](#)

Japanese

[Application Specification](#)

English

[MTA 156 Ribbon Cable Connector Assemblies \(English And Spanish\)](#)

English

[MTA 156 Ribbon Cable Connector Assemblies \(English And Spanish\)](#)

Japanese