


AC5010



Lower part for AS-Interface module

EMS-Base FC Addressing socket

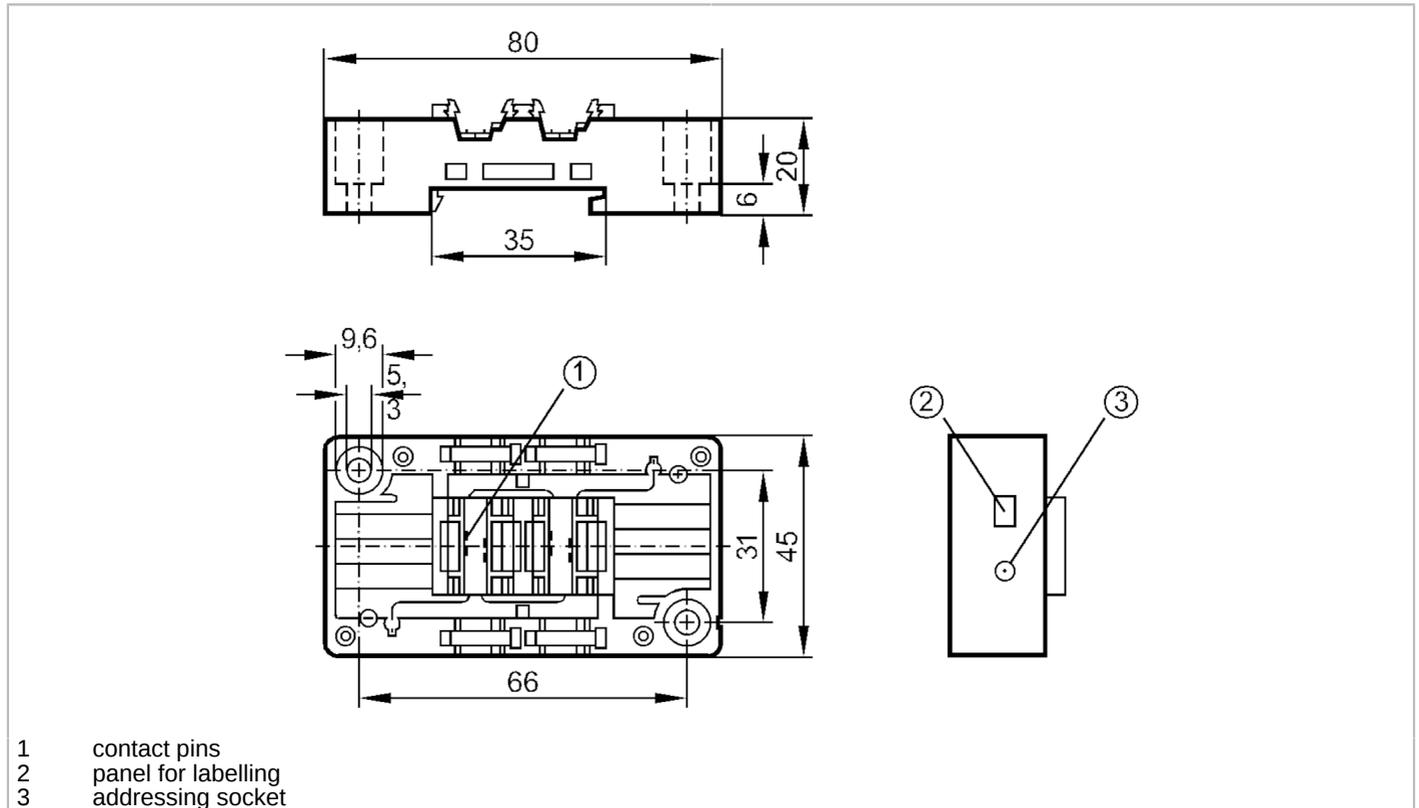

Electrical data	
Operating voltage	[V] 26.5...31.6 DC
Outputs	
Electrical design	AS-i
Contact rating	< 2 A
Operating conditions	
Ambient temperature	[°C] -25...85
Protection	IP 67; (depending on the upper part used: IP 20 / IP 65 / IP 67)
AS-i classification	
AS-i addressing	addressing socket
Mechanical data	
Weight	[g] 59.5
Housing	rectangular
Type of mounting	mounting on DIN rail and panel
Dimensions	[mm] 45 x 80 x 20
Materials	PBT
Remarks	
Pack quantity	1 pcs.
Electrical connection	
contact pins in module upper part :	
quick mounting technology for AS-i flat cable:	