


Tapered roller bearings, single row

Principal dimensions			Basic load ratings		Speed ratings	Limiting speed	Designation
d	D	T	dynamic C	static C0	Reference speed		* SKF Explorer bearing
mm			kN		r/min		-
33,338	68,262	22,225	55	69,5	7500	11000	M 88048/2/010/2/QCL7

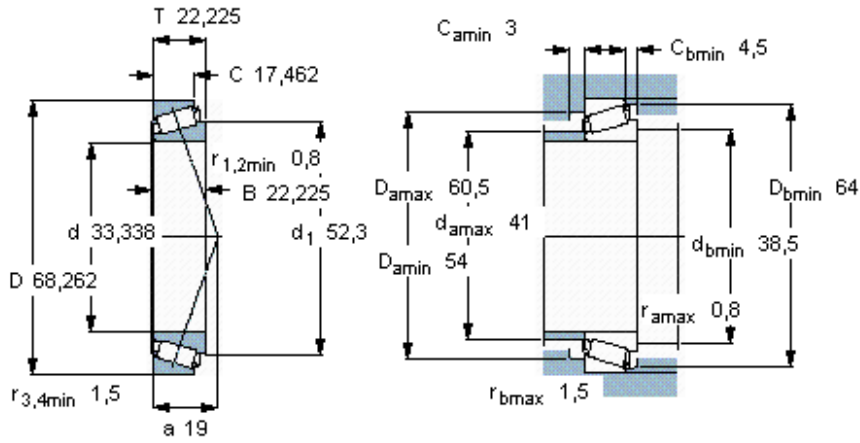

Calculation factors

e 0,54

Y 1,1

Y_0 0,6