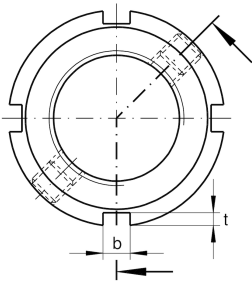
**ZM08** **Precision locknut**

Precision locknut ZM, accessory ZM..

Technical information**Main Dimensions & Performance Data**

d	M8X0,75	Thread
D	16 mm	Outside diameter
h	8 mm	Height
M _A	1 Nm	Mounting torque set screw
F _{aB}	23,000 N	Breaking load, axial
M _L	25 Nm	Breakawag
M _{AL}	4 Nm	Mounting torque reference
M _M	0.004 kg*cm ²	Mass moment of inertia
≈m	7.346 g	Weight

Dimensions

d ₁	11 mm	Plant diameter outside
t	2 mm	Hight retaining slot
b	3 mm	Width retaining slot
c	4 mm	Distance bore
m	M4	Threaded - threaded pin