

# Expression Home XP-322



## DATASHEET



The Expression Home XP-322 is part of Epson's smallest ever range of small-in-one home inkjets. This printer, scanner and copier offers cost-effective printing through the use of inks that can be replaced individually. An LCD colour screen makes using the XP-322 clear and easy, while Wi-Fi compatibility and mobile printing allow printing from anywhere<sup>1</sup>.

### Efficient & affordable

Epson's Claria Home Ink is ideal for affordable and reliable printing, producing crisp, clear text documents and glossy, lab-quality photos. The use of individual ink cartridges mean you only have to replace the colour used, saving you money.

### Easy set-up


The automatic Wi-Fi set-up<sup>2</sup> makes configuring laptops and computers to print and scan wirelessly extremely easy. You don't need to know your network settings as the XP-322 automatically finds the relevant connection settings in order to configure itself. For added versatility, Wi-Fi Direct<sup>®</sup> allows easy printing from compatible wireless devices without the need for a network.

### Mobile printing

The XP-322 comes with Epson Connect<sup>1</sup> which consists of Epson iPrint<sup>1</sup> – for easy wireless printing from smartphones and tablets; Epson Creative Print<sup>1</sup> – print photos directly from Facebook and Epson Email print<sup>1</sup> – print from anywhere in the world by emailing photos and documents directly to the printer. AirPrint<sup>3</sup> and Google Cloud Print are also supported.

## KEY FEATURES

- **Small-in-one**  
Save space, save money, save time
- **Wi-Fi Direct™**  
Wireless printing without a network
- **Epson Connect**  
Freedom to print and scan from anywhere
- **PC-free printing**  
3.7cm colour LCD screen
- **Claria Home Ink**  
Crisp, clear text and glossy photos

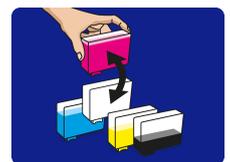

## PRODUCT SPECIFICATIONS

### TECHNOLOGY

Printing Method	Epson Micro Piezo™ print head
Nozzle Configuration	180 Nozzles black, 59 Nozzles per colour
Minimum Droplet Size	3 pl, With Variable-Sized Droplet Technology
Ink Technology	Claria™ Home Ink
Printing Resolution	5,760 x 1,440 dpi
All-in-One Functions	Print, Scan, Copy
Category	Consumer

### PRINT

Printing Speed ISO/IEC 24734	9 Pages/min Monochrome, 4.5 Pages/min Color
Maximum Printing Speed	38 Seconds per 10 x 15 cm photo (Epson Premium Glossy Photo Paper), 33 Pages/min Monochrome (plain paper), 15 Pages/min Color (plain paper)
Colours	Black, Cyan, Yellow, Magenta

For detailed information on printing speeds please visit <http://www.epson.eu/testing>.

### SCAN

Single-sided scan speed (A4 black)	300 dpi 2.4 msec/line; 600 dpi 7.2 msec/line
Single-sided scan speed (A4 colour)	300 dpi 9.5 msec/line; 600 dpi 14.3 msec/line
Scanning Resolution	1,200 dpi x 2,400 dpi (Horizontal x Vertical)
Scanner type	Contact image sensor (CIS)

### PAPER / MEDIA HANDLING

Number of paper trays	1
Paper Formats	A4, A5, A6, B5, C6 (Envelope), DL (Envelope), No. 10 (Envelope), Letter Legal, 9 x 13 cm, 10 x 15 cm, 13 x 18 cm, 13 x 20 cm, 20 x 25 cm, 100 x 148 mm, 16:9
Duplex	Manual
Print Margin	0 mm top, 0 mm right, 0 mm bottom, 0 mm left (Wherever margin is defined. Otherwise 3mm top, left, right, bottom.)
Paper Tray Capacity	100 Sheets Standard, 20 Photo Sheets

### GENERAL

Energy Use	ENERGY STAR® qualified, 13 W (standalone copying, ISO/IEC 24712 pattern), 1.6 W (sleep mode)
Supply Voltage	AC 220 V - 240 V
Product dimensions	390 x 300 x 145 mm (Width x Depth x Height)
Product weight	4.2 kg
Noise Level	4.9 B (A) with Epson Premium Glossy Photo Paper / Photo RPM mode - 36 dB (A) with Epson Premium Glossy Photo Paper / Photo RPM mode

## LOGISTICS INFORMATION

SKU	C11CD90401
EAN code	8715946539645
Dimensions Single Carton	455 x 192 x 365 mm
Carton Weight	5.2 Kg
Multiple Order Quantity	1 Units
Country of Origin	Thailand
Pallet Size Euro	49 Units
Pallet Size Block	66 Units



For more information please contact:

Telephone: 01952 607111 (UK)+  
01 436 7742 (Republic of Ireland)  
E-mail: [enquiries@epson.co.uk](mailto:enquiries@epson.co.uk)  
Chat: [etalk.epson-europe.com](http://etalk.epson-europe.com)  
Fax: 0871 222 6740  
+ Local call rate.

Web: [www.epson.co.uk](http://www.epson.co.uk)  
[www.epson.ie](http://www.epson.ie)

Trademarks and registered trademarks are the property of Seiko Epson Corporation or their respective owners. Product information is subject to change without prior notice.

## Expression Home XP-322

### WHAT'S IN THE BOX

- Software (CD)
- Setup guide
- Power cable
- Main unit
- Individual Ink Cartridges
- Warranty document

### INK CARTRIDGE COMPATIBILITY



### INK YIELD DATA

	470 pages*	175 pages*
	450 pages*	
		180 pages*
		450 pages*

\* Approx. page yield based on ISO/IEC 24711/24712 or ISO/IEC 29102/29103. Actual yield will vary depending on images printed and usage conditions. For more information visit <http://www.epson.eu/pageyield>

1. – Epson iPrint and Epson Creative Print require a wireless connection and the Epson printing apps. Email print and Epson Remote Print Driver require an internet connection. For more information, supported languages and devices, please visit [www.epsonconnect.eu](http://www.epsonconnect.eu) 2 – Automatic set-up compatible with Windows 8, Windows 7, Windows Vista and Mac OS 3 – AirPrint-enabled printers work with iPad (all models), iPhone (3GS or later), and iPod touch (3rd generation or later) running the latest version of iOS.

