





LED Ecoplus T8 361 G13 5W (14W) 700lm 840 EM+AC

Article number: 147201

BAI Ecoplus T8 LED Tube 26x36mm G13 5W (14W) 4000K 700lm Glass EM Retrofit + AC 230V-240V 250° Temp. -20°C +25°C LED-lamp Alt T26 TLD Lumilux

LED T8 tube with a G13 fitting, ideal to replace standard 14W T8 fluorescent tubes. This Ecoplus version has a high efficient lumen output (HE). So with less energy a comparable lumen value like our ecobasic version. Installation: Disconnecting magnetic ballast is optional, not necessary. Not suitable for series connection. Replace the fluorescent starter with the LED starter (supplied). Ambient temperature range: -10°C to +45°C.

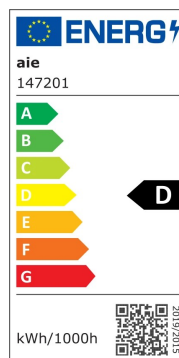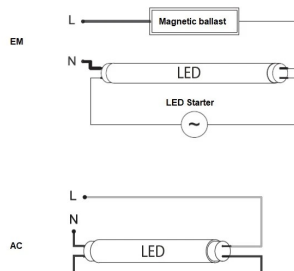

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED Ecoplus T8 361 G13 5W (14W) 700lm 840 EM+AC
Brand	Bailey
Productseries	Ecoplus LED tube
Producttype	T8 361 840

ETIM specifications

Socket	G13
Luminous flux [lm]	700 - 700
Nominal voltage [V]	220 - 240
Lamp power [W]	5 - 5
Colour temperature [K]	4000 - 4000
Diameter [mm]	26
Length [mm]	361
Dimmable	No
Lamp shape	Tube, double-ended
Beam angle [°]	250 - 250
Colour	White
Type of glass/cover	Opal
Lamp designation	T8
Colour rendering index CRI	80-89
Voltage type	AC
Filament lamp	No
Rated luminous flux according to IEC 62612 [lm]	700
Power factor	0.9
Lamp efficacy [lm/W]	140
Nominal current [mA]	25 - 25
Colour of light according to EN 12464-1	Neutral white 3300-5300 K
Housing colour	White
Average nominal lifetime [h]	25000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM5
Min. number of switching cycles	15000
Weighted energy consumption in 1000 hours [kWh]	5
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG0
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	Yes
Dimming phase cut-off (trailing edge)	No
Dimming phase cut-on (leading edge)	No
Dimming Touch and Dim	No
Dimming Zigbee	No

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	D
With twilight switch	No
Material of light bulb	Glass