



UN38.3 试验概要 UN38.3 Test Summary



812000300101420

单位信息 Company information			
委托单位 Consignor	东莞市拓步电子有限公司 DongGuan TUOBU ELECTRONIC CO.,LTD 广东省东莞市黄江镇田心村滨河路6号A栋 NO.6 Building A binhe Road Tianxin Village Huang Jiang Town Dongguan City,Guangdong 13924673080 HIGHESTSZ@126.com http://www.highestsz.com/		
生产单位 Manufacturer	东莞市拓步电子有限公司 DongGuan TUOBU ELECTRONIC CO.,LTD 广东省东莞市黄江镇田心村滨河路6号A栋 NO.6 Building A binhe Road Tianxin Village Huang Jiang Town Dongguan City,Guangdong 13924673080 HIGHESTSZ@126.com http://www.highestsz.com/		
测试单位 Test lab	威凯检测技术有限公司 Vkan Certification & Testing Co., Ltd.(CVC) 广州市萝岗区天泰一路3号 No.3, Tiantaiyi Road, Kaitai Avenue, Science City, Guangzhou, 510663, P. R. China 020-32293851 dengjz@cvc.org.cn http://www.cvc.org.cn		
电池信息 Battery information			
名称 Name	锂-二氧化锰电池 Lithium Manganese Dioxide Button Cell	品牌 Brand	/
型号 Type	CR2450	原始测试型号 Original tested type	/
标称电压(V) Nominal voltage	3	容量/能量 Capacity/energy	630mAh
描述 Description	不可充电锂金属电池芯 Primary Li-metal cell	锂含量(g) Li content	0.18
质量(kg) Mass	0.00622	外观 Appearance	银色钮扣状金属外壳 Silvery button metal shell
测试信息 Test information			
原报告编号 Original test report No.	RZUN2016-4077	测试报告日期 Date of test report	2017-01-09
测试标准 Test standard	联合国《关于危险货物运输的建议书 试验和标准手册》第38.3章 UNITED NATIONS "Recommendations on the TRANSPORT OF DANGEROUS GOODS" Manual of Tests and Criteria 38.3 ST/SG/AC.10/11/Rev.6		
T.1 高度模拟 Altitude simulation	合格 Passed	T.2 温度测试 Thermal test	合格 Passed
T.3 振动测试 Vibration	合格 Passed	T.4 冲击测试 Shock	合格 Passed
T.5 外部短路 External short circuit	合格 Passed	T.6 挤压 Crush	合格 Passed
T.7 过度充电 Overcharge	/	T.8 强制放电 Forced discharge	合格 Passed
38.3.3 (f)	/	38.3.3 (g)	/



声 明

Statement

1. 试验概要无本实验室公章（或检验检测专用章）无效。

The test summary is invalid if it is not affixed the official seal of the laboratory to it.

2. 复制试验概要未重新加盖本实验室公章（或检验检测专用章）无效。

Copies of the test summary without the official seal of the laboratory are invalid.

3. 试验概要无签字及签字者姓名和职务无效。

The test summary is invalid without the signature, name and title of the signatory.

4. 试验概要涂改无效。

The test summary is invalid if it is blotted out.

5. 未经本实验室书面批准，不得部分复制试验概要。

It is forbidden to copy the test summary partially without the written approval of the laboratory.

6. 试验概要中描述的检测结果，仅对所测样品有效。

The conclusion of the test summary is only valid for the tested sample.

7. 试验概要以中文为准，英文文本（如有）仅为译文，两者发生冲突时，应以中文文本为准。

The test summary has been drafted in Chinese and translated into English (if exist) for convenience only. In the event of discrepancy, the Chinese version shall prevail.

地址：上海市云岭东路 345 号 Address: No. 345 East Yunling Road, Shanghai

邮政编码(PostCode): 200062

电话(Tel): (021) 31765555 传真(Fax): (021) 31015117


网址(website): www.ghs.cn

 
电子信箱(E-mail): battery@ghs.cn



扫描全能王 创建

样品图片 Sample Picture

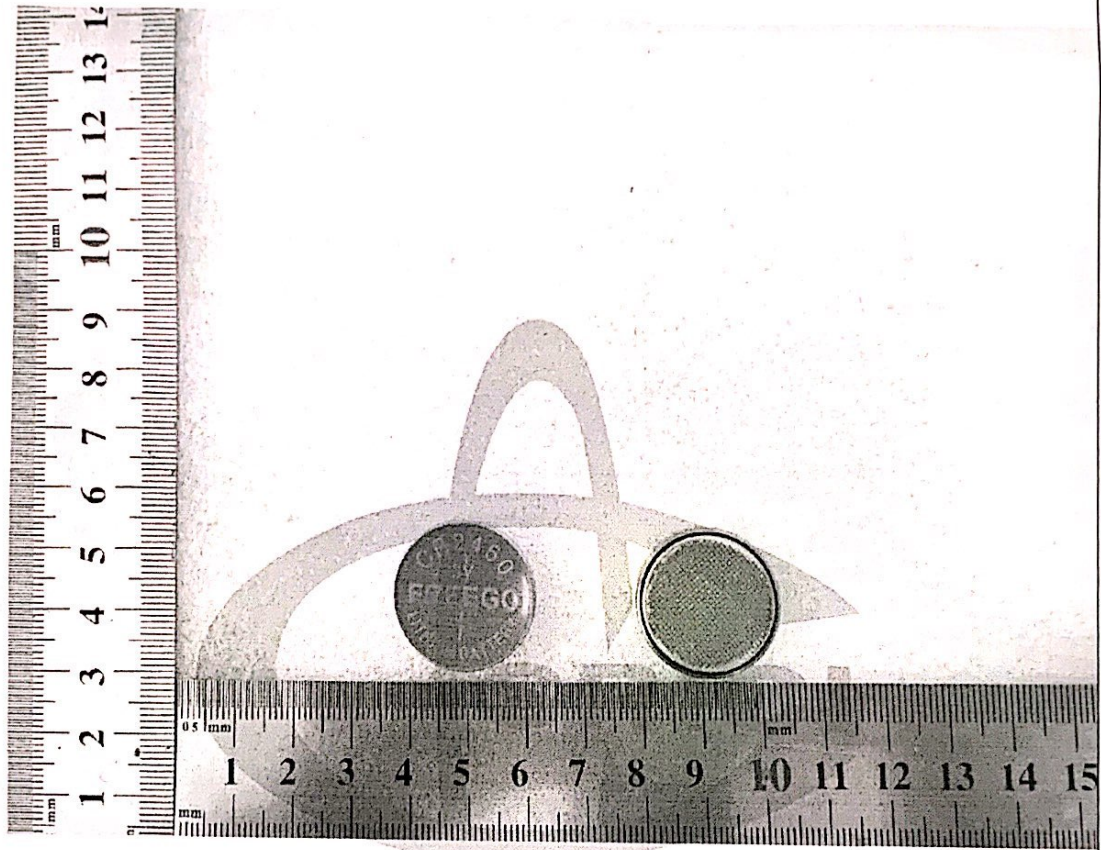

结论 Conclusion	测试样品符合联合国《关于危险货物运输的建议书试验和标准手册》ST/SG/AC.10/11/Rev.6 38.3 标准要求。The tested samples meet the requirements of test items of the UNITED NATIONS "Recommendations on the TRANSPORT OF DANGEROUS GOODS" Manual of Tests and Criteria ST/SG/AC.10/11/Rev.6 38.3	
备注 Remark	/	
签名 Signature 职务 Title	 王寅 副总工程师 Vice chief engineer	签发日期 Issued date 2020-01-05 

-验证码:492263-

报告结束

