



Technical data

BK2538ZWD

Drawn cup needle roller bearings, closed end

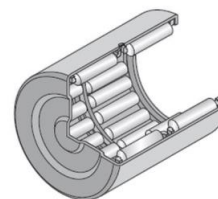

VISUAL (S)

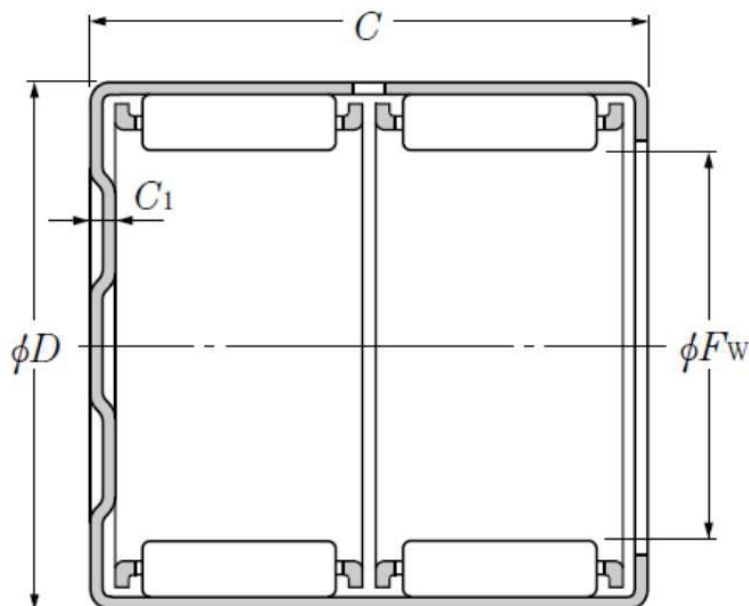

PRODUCT DEFINITION

Brand	NTN
Fw - Under rollers diameter	25 mm
D - External diameter	32 mm
C - Width of bearing, drawn cup or outer ring	38 mm
C1 - Max drawn cup closed end thickness	2,7 mm
Lubrication hole on outer ring	Oui/Yes
k - Hole diameter	2,5 mm
Inner ring reference	IR20X25X38.5
Mass	0,069 kg



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

BK2538ZWD

Drawn cup needle roller bearings, closed end

PRODUCT PERFORMANCE

Cr - Dynamic load rating	35000000 mN
C0r - Static load rating	65500000 mN
N lim - Grease lubrication limit speed	39000 °/s
N lim - Oil lubrication limit speed	57000 °/s
Tmin - Min operating temperature	253,15 °K
Tmax - Max operating temperature	393,15 °K



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15