



Datasheet Screwdrivers RS Soft Grip Screwdrivers

Parallel tip soft grip screwdrivers with Chrome Vanadium Steel blades.


- Blackened tip
- Injection moulded handle



Stubby



Standard

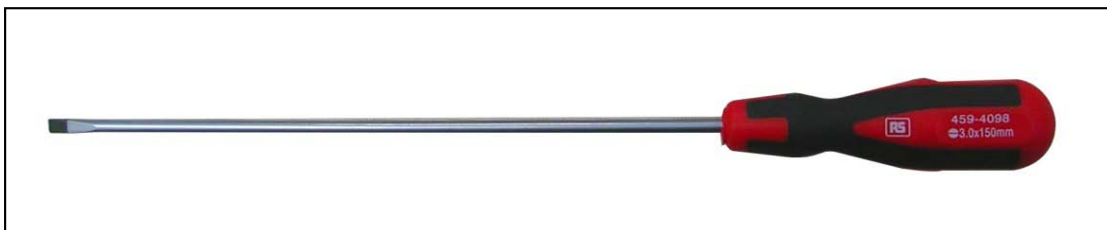

Long Reach

Technical Details				
RS Stock No.	Type	Tip Type	Tip Size	Blade Length (mm)
459-3994	Stubby	Flared	6 mm	40 mm
459-4010	Standard	Flared	5 mm	100 mm
459-4032	Standard	Flared	6 mm	150 mm
459-4048	Standard	Flared	8 mm	150 mm
459-4054	Long Reach	Flared	8 mm	200 mm
459-4060	Long Reach	Flared	10 mm	250 mm