


Product data sheet

Specifications

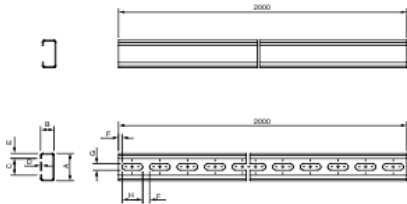

Symmetric C-shaped rails drilled
40x20x24. Length 2000mm. Supply:
20 rails 2m.

NSYCNT40

Main

| | |
|------------------------------------|----------------------|
| Anwendung | Multi-purpose |
| Range | Spacial |
| Product or component type | Rail |
| Accessory / separate part category | Mounting accessory |
| Type of rail | Symmetrical C-shaped |
| Enclosure nominal dimensions | - |
| Range compatibility | Spacial Thalassa |
| Device composition | 1 rail |
| Quantity per set | Set of 10 |

Complementary

| | |
|----------------|-------------------|
| Material | Galvanised steel |
| Surface finish | Perforated |
| Fixing mode | By fixing element |
| Length | 2000 mm |
| Height | 40 mm |
| Width | 20 mm |
| Thickness | 1.5 mm |

Packing Units

| | |
|------------------------------|----------|
| Unit Type of Package 1 | PCE |
| Number of Units in Package 1 | 1 |
| Package 1 Weight | 1.875 kg |
| Package 1 Height | 2 cm |
| Package 1 width | 4 cm |
| Package 1 Length | 200 cm |
| Unit Type of Package 2 | CAR |
| Number of Units in Package 2 | 20 |

| | |
|------------------|---------|
| Package 2 Weight | 37.5 kg |
| Package 2 Height | 11.5 cm |
| Package 2 width | 10 cm |
| Package 2 Length | 201 cm |

Offer Sustainability

| | |
|----------------------------|---|
| Sustainable offer status | Green Premium product |
| REACH Regulation | REACH Declaration |
| REACH free of SVHC | Yes |
| EU RoHS Directive | Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration |
| Toxic heavy metal free | Yes |
| Mercury free | Yes |
| RoHS exemption information | Yes |
| China RoHS Regulation | China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope) |
| Environmental Disclosure | Product Environmental Profile |

Contractual warranty

| | |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|