


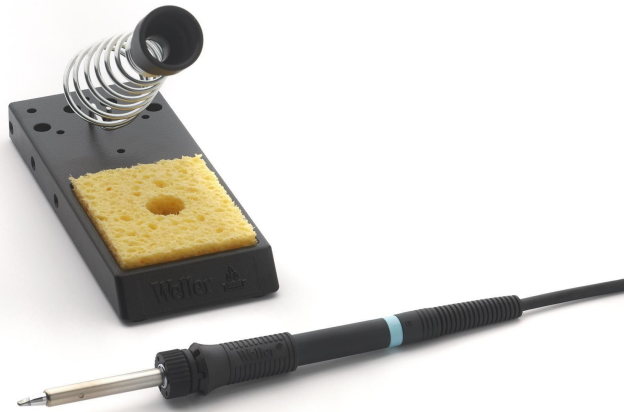

WSP80 Set

Item No: T0053312599N

Soldering iron WSP 80 with safety rest

KEY FEATURES

- + Soldering Iron 80 W, 24 V with knurled nut for fast tip exchange
- + For medium components with high energy demand
- + For universal soldering jobs with WT stations and WR rework stations
- + Extensive range of LT soldering tips
- + Silver-Line heating technology
- + Fast heating up

TECHNICAL DATA

Approximate Heating Time (50–350 °C/120–660 °F)	10 sec
Barrel	T0058744710
ESD Safe	Yes
Inert Gas Function	T0058744847
Integrated Direct Extraction	T0052918699 T0052918599
Power	80 W
Silver Line Heating Element Technology	Yes
Supply Unit	PU81 PUD81 PUD81i PUWAD101 PUD121 PUWAD101IG PUD151 WD1 WD1M WR2 WR3M WR3ME WT1 WT1H WT2M
Temperature Range (Depends on Tool)	50 - 450°C
Temperature Range °C	50 - 450 °C
Temperature Range °F	150 - 850 °F
Tip Range	LT
Tip Type	LT
UPC	037103309310
Product Family	WT Soldering Irons