



Brand of NTN corporation


Technical data

BBE8UU

Standard ball bushings closed



VISUAL (S)

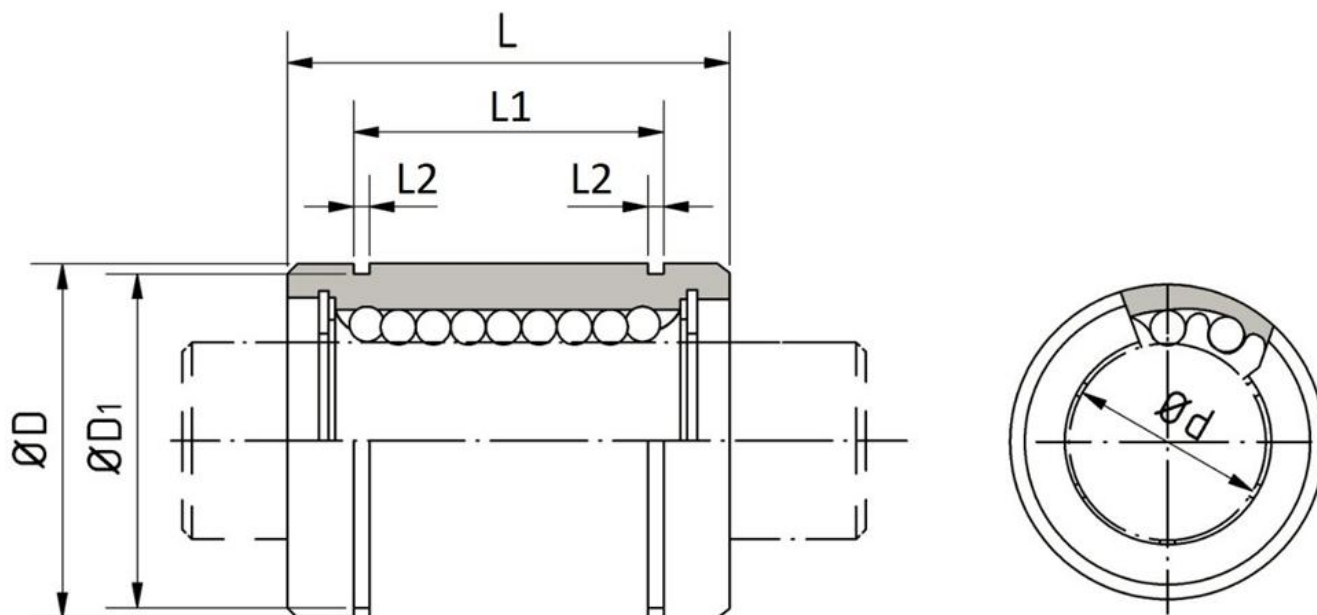

PRODUCT DEFINITION

Brand	SNR
Design type	BBE
Ball bushings category	Standard ball bushings, closed
Standard	ISO dimension
Number of seals	2
Material outer cylinder or steel segments	100Cr6
Material Cage	PA
Initial greasing	Non/No
d - Internal diameter	8 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION	
d - Internal diameter tolerance	0.008/0
D - External diameter	16 mm
D - External diameter tolerance	0/-0,008
L - Length	25 mm
L - Length tolerance	0/-0,2
L1	16,5 mm
L1 tolerance	0/-0,2
D1 - Diameter	15,2 mm
L2	1,1 mm
Number of ball rows	4
Mass	0,022 kg

PRODUCT PERFORMANCE	
Cmin	0,195 kN
Cmax	0,276 kN
C0min	0,402 kN
C0max	0,568 kN
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	80 °C

ESHOPDONOTDISPLAY	
Reference	BBE8UU
Image	BBE+BB_1.JPG, BBE+BB_3.JPG
Send to Eshop	Yes
Send to Paper Catalog	Yes



ESHOPDONOTDISPLAY

Tracepart

Oui/Yes

