



Figure similar

SITOR cylindrical fuse link, 22x58 mm, 80 A, gR, Un AC: 690 V, Un DC: 250 V

Model		
product brand name	SETRON	
product designation	SITOR cylindrical fuse link	
General technical data		
operating class of the fuse link	gR	
type of voltage of the operating voltage	AC	
supply voltage at DC	250 V	
Main circuit		
operational current rated value	80 A	
Product details		
product component striker	No	
Mechanical Design		
mounting position	Any, preferably vertical	
net weight	55 g	
Approvals Certificates		
General Product Approval	other	Environment




[Confirmation](#)

[Environmental Con-
firmations](#)

[Environmental Con-
firmations](#)

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
Information- and Downloadcenter (Catalogs, Brochures,...)
<http://www.siemens.com/lowvoltage/catalogs>
Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3NC2280-0MK>
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/3NC2280-0MK>
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)
http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NC2280-0MK
CAx-Online-Generator
<http://www.siemens.com/cax>
Tender specifications
<http://www.siemens.com/specifications>

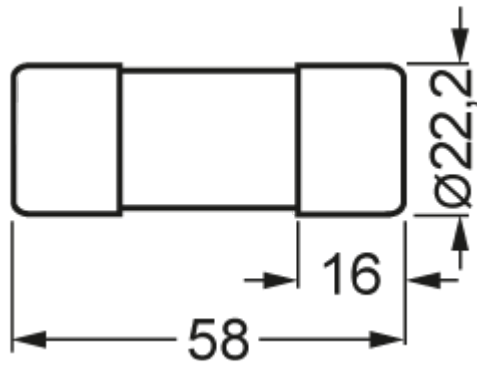

last modified:

4/11/2025 [↗](#)

