



Application Tooling > Insertion & Extraction Tools



Insertion & Extraction Tool Type: **Contact Extraction**
Insertion & Extraction Tool Application: **Contact-to-Housing**

Features

Product Type Features

Insertion & Extraction Tool Type	Contact Extraction
Insertion & Extraction Tool Application	Contact-to-Housing

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

 
 
 
Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides



on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

 TE Part # 7-1718350-3 MCON 1.2 TAB-CB ASSY	 TE Part # 7-1718350-1 MCON 1.2 TAB-CB ASSY	 TE Part # 7-1670144-2 MCON 1.2 CB REC SRC AU	 TE Part # 7-1670144-1 MCON 1.2 CB REC SRC SN
 TE Part # 2373781-5 MCON,CABLE ASSY,F TO F, 5000MM	 TE Part # 2373781-3 MCON,CABLE ASSY,F TO F, 1500MM	 TE Part # 2373781-2 MCON,CABLE ASSY,F TO F, 1000MM	 TE Part # 2373785-5 MCON,CABLE ASSY,M TO F, 5000MM
 TE Part # 2373785-2 MCON,CABLE ASSY,M TO F, 1000MM	 TE Part # 2373785-3 MCON,CABLE ASSY,M TO F, 1500MM	 TE Part # 2366735-1 2PORT,HYBRID,HDR ASSY,180DEG, COD A,COD B	 TE Part # 7-1670144-3 MCON 1.2 CB REC SRC AG
 TE Part # 2373785-4 MCON,CABLE ASSY,M TO F, 3000MM	 TE Part # 2298567-1 22POSN.,REC ASSY, MCON1.2, MQS, MCP2.8	 TE Part # CAT-M4595-T273 MCON Receptacle and Tab	 TE Part # 7-1718350-2 MCON 1.2 TAB-CB ASSY



TE Part # 2373781-4
MCON, CABLE ASSY, F TO F, 3000MM



TE Part # 2366735-3
2PORT, HYBRID, HDR ASSY, 180DEG, COD A, COD B




TE Part # CAT-AI5-EH
enetSEAL+ Ethernet Connector Housings


Also in the Series | MCON Interconnection System




Automotive Connector Caps & Covers (36)

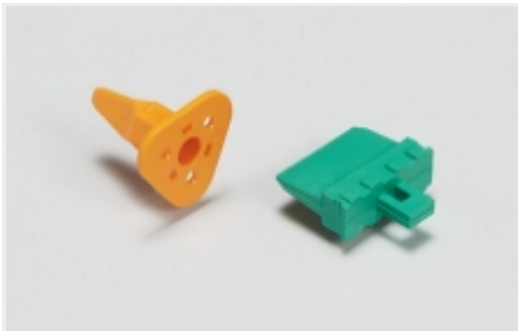

Automotive Connector Locks & Position Assurance (15)

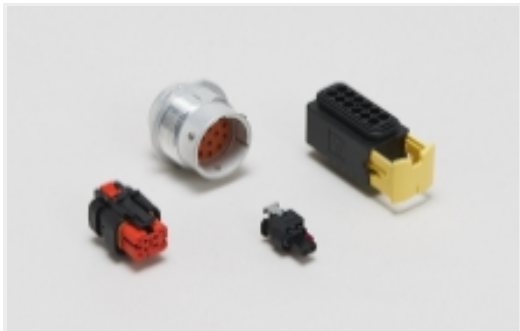

Automotive Housings (126)

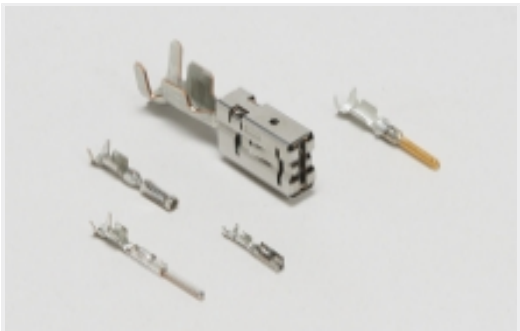


Automotive Terminals (22)



Connector Seals & Cavity Plugs (8)



Other Automotive Connector Accessories (4)

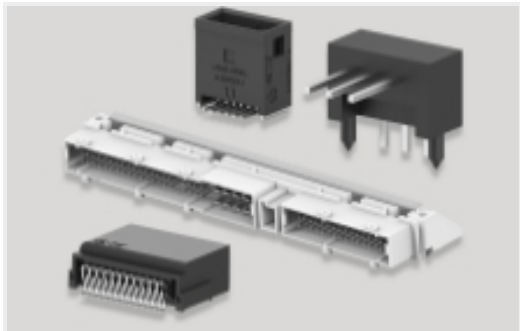

PCB Headers & Receptacles (3)



Rectangular Power Connectors (1)

Customers Also Bought



TE Part #5-1633918-3
ANVIL, COMBINATION



TE Part #1717138-5
025/040 SEALED 44POS PLUG ASSY



TE Part #2383363-1
TPA TAB HSG ASSY, 95POS, LEAVYSEAL, SLD



TE Part #2292906-1
2POS, MCON 1.2, REC HSG ASSY, SLD, COD A




TE Part #1-1718290-1
CLIP SPRING



TE Part #K1127118
Battery Disconnect 35-521-100-R



TE Part #965687-1
FIXING RING

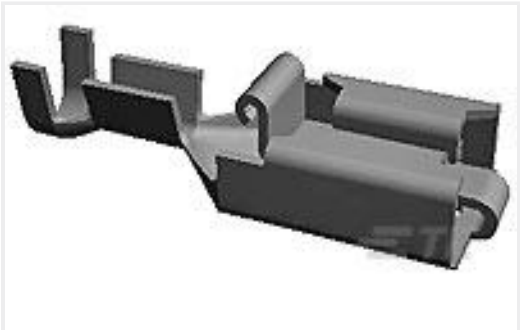

TE Part #880645-6
PL REC 1.0-2.5MM2 0.40 X 52.32 PTPBR



Documents

Product Drawings

[EXT TOOL, MCON 1.2 CB](#)

English

CAD Files

[3D PDF](#)

3D

Customer View Model

[ENG_CVM_CVM_2844610-1_A.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2844610-1_A.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2844610-1_A.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Instruction Sheets

[Instruction Sheet \(U.S.\)](#)

English