


Honeywell

18" (45cm) commercial grade high velocity fan

HV-180 black and chrome

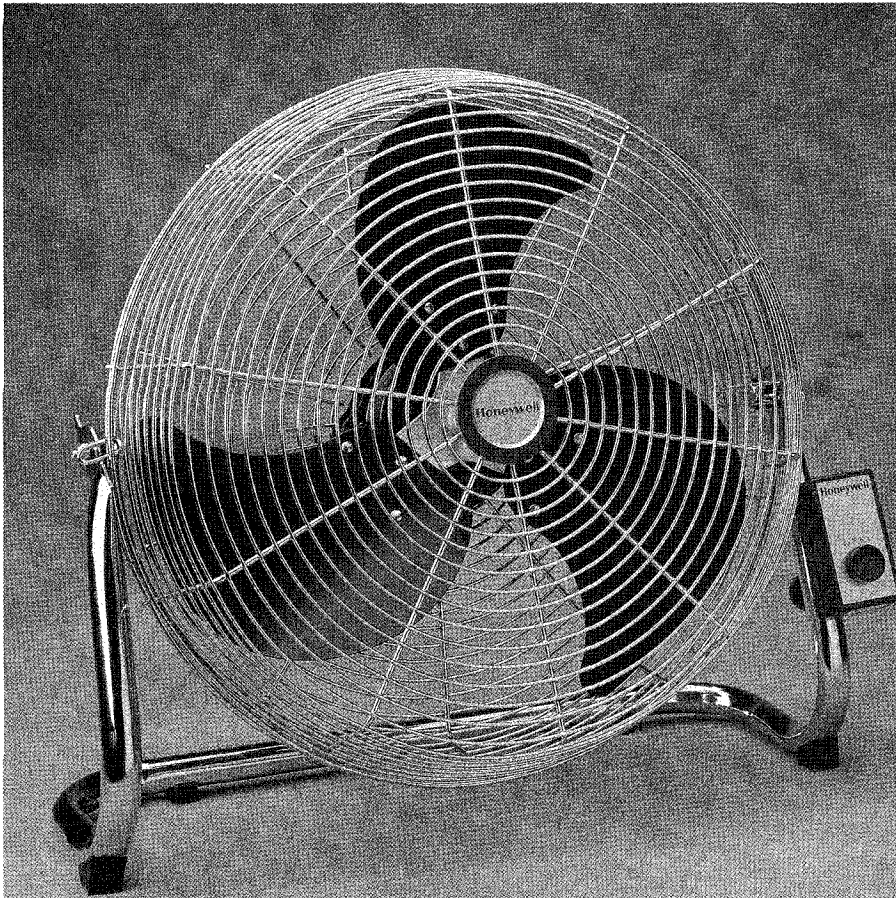

- *rugged all metal construction*
- *designed for commercial use*
- *can provide whole home cooling*
- *powerful 3 speed motor (super-hi-lo) for rapid cooling*
- *4 position easily accessible front control*
- *air flow adjustment*
- *tilts back to air circulator position*
- *chrome grill*
- *all metal fan blades*


**Rugged all metal construction
designed for commercial use**



HV-180 black and chrome 18" (45cm) commercial grade high velocity fan

Sales Information

Honeywell welcomes your call for further information or to receive literature and other sales support material:
telephone no: 0345 66034

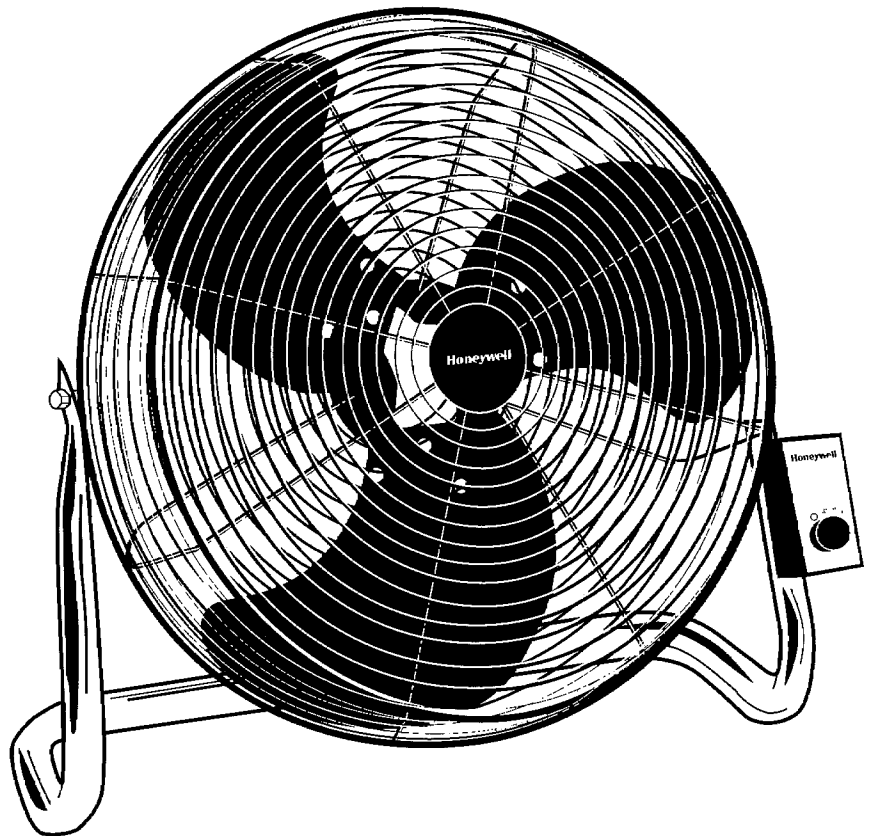

Order code	HV180
EAN number	40 22167 5180 19
Blade size in/cm	18in/45cm
Output watts	135
Voltage/frequency V~/Hz	230/50
Control positions	4
Blade	chrome
Number in master pack	1
Pack size cm (LxWxH)	58.2 x21.5 x 56.0
Pack weight kg	19.69kg
Full colour packaging	

Honeywell

Honeywell Consumer Products Limited
Centre Court, Vine Lane
Halesowen B63 3EB
telephone 0121 5505038
facsimile 0121 5505477

Helping You Control Your World