
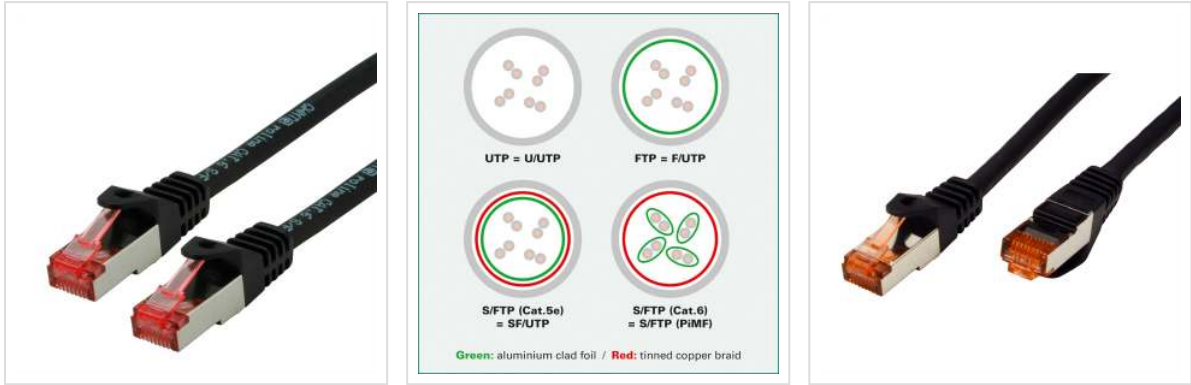


ROLINE S/FTP Patch Cord Cat.6 Component Level, LSOH, black, 10 m

Product No.	21.15.2657	 Designed for Professionals
Manufacturer	ROLINE	
Manufacturer No.	21.15.2657	
EAN (single piece)	7611990135950	



Cat.6

S/FTP

LSOH

COMPONENT
Level Tested

Patch cable for networking connections between devices. Prepared double shielded Twisted Pair cable with screened RJ-45 connectors on both ends. Durable due to moulded kink protection. Flexible cable, suitable for narrow bending. High quality plugs with gold plated contacts. Contact settings 1:1, in accordance with the EIA/TIA 568 standard. Construction: 4-pair stranded copper wire. Complete braid shielding. Pairs shielded with aluminium clad polyester foil. Halogen-free, flame retardant, low smoke.

100% Component Level testing

Technical specifications	
Manufacturer	ROLINE
Product group	Twisted Pair Cable
Product type	S/FTP Patchcord
Colour	black
Length	10 m
Shield type	SFTP

Transfer quality	Cat6 / Class E
Component-Level certified	Yes
Impedance	100 Ohm
Quantity of wires	8
Conductor type	Wire
Crossed	No
Colour (Spout)	black
Cable LSOH	Yes
Side 1 Connector Type	RJ-45
Side 1 Connector Gender	Male
Side 2 Connector Type	RJ-45
Side 2 Connector Gender	Male
Connector Type RJ45	Standard