


# ST45 450W SOLDERING IRON

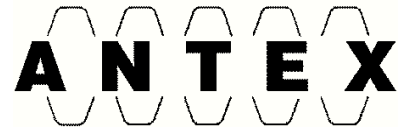


## DATA SHEET

769-3081



### **SPECIFICATIONS ST45 (STRAIGHT) 450WATT SOLDERING IRON**

NOMINAL POWER (W)	450
STANDARD VOLTAGE	230
NOMINAL TIP TEMP (°C)	440
FITTED BIT (D.F.)	1 1/4" (32mm)
CABLE LENGTH (m)	2.0
CABLE TYPE	Rubber with British plug
HANDLE MATERIAL	Wood
COUNTRY OF ORIGIN	U.K.
WEIGHT gms. (approx.)	1650
DIMENSIONS (approx)	A: (bit) 80mm. B: (handle & element) 330mm.

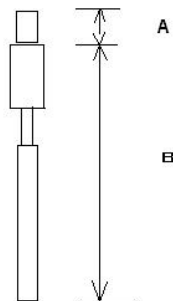

#### **TYPICAL APPLICATIONS:**

Heavy duty tasks. Features large bit with rapid heat replacement. Extensively used for heavy maintenance work including electronic motors with high temperature alloys, radiator manufacture, large metal boxes and for joining busbars.