
**LR5205-X-2Z-TVH-XL**

Galet de roulement

Yoke type track rollers LR52...-2Z-TVH-XL, double row self-retaining angular contact ball bearings with particularly thick-walled outer ring, ball and cage assembly and an inner ring, axial guidance of outer ring is provided by the balls, lubrication hole in inner ring on request, sealing shield on both sides, cage made from glass fibre reinforced polyamide, X-life design

X-life

Information technique

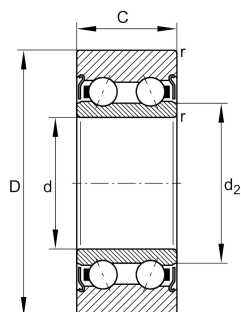

Votre alternative produit actuelle

joint	2Z	Défecteur des deux côtés
profile bague extérieure	X	Diamètre extérieur cylindrique
dispositif de lubrification	Without	Without
Cage	TVH	Cage polyamide renforcée fibre de verre

dimensions principale & données de performance

D	62 mm	Diamètre extérieur
d	25 mm	Alésage
C	20,6 mm	Hauteur
C _{r w}	19.700 N	Charge dyn. de base, radiale
C _{0r w}	15.800 N	Charge stat. de base, radiale
C _{ur w}	810 N	Limite à la fatigue, radiale
n _{D G}	6.500 1/min	Vitesse pour une lubrification à la graisse
F _{r per}	15.800 N	Charge radial dynamique admissible sur bague extérieure
≈m	0,34 kg	Poids

Dimensions

d ₂	34,2 mm	Diamètre rondèle de butée
r _{min}	1 mm	Dimension minimum de chanfrein
R	500 mm	Rayon bague extérieure profile externe