



Brand of NTN corporation

Technical data

EXFCE212

Bearing units




Grey cast housing, radial insert ball bearing with eccentric locking collar, seal with slinger

KIT CONTENT

EX212G2, FCE212

VISUAL (S)

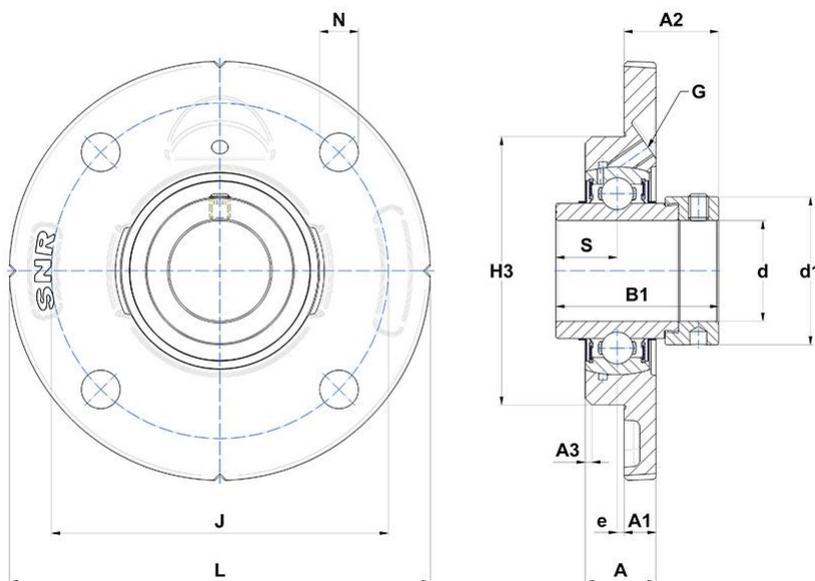

PRODUCT DEFINITION

Brand	SNR
A - Housing height	30,5 mm
A1 - Housing foot height / flange height	16 mm
A2 - Total height from mounting surface	45,8 mm
A3 - Centering depth / chamfer dimension	3 mm
B - Width of Inner Ring	61,8 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

B1 - Overall width Inner Ring	77,7 mm
d - Shaft diameter	60 mm
d1 - Outer dia of eccent. Lock. collar / nut of adapter sleeve	82 mm
e - Distance mounting surface to bearing center	-1 mm
G - Grease fitting	R1/8"
H3 - Centering dia	135 mm
J - Mounting holes distance	160 mm
L - Housing width / diameter	195 mm
N - Mounting hole dimension	18 mm
S - Distance front side/bearing centre	30,9 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	52500000 mN
C0 - Static load rating	32800000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	4,2 kg
Recommended tightening torque for set screw	22 N-m

