

ToLEDo Retro Chroma A60 Green E27 SL

Item No: 0086309


SYLVANIA



- Each LED filament is coated with a unique coloured fluorescent phosphor creating the most intense and saturated colours on the market, - Clear outer A60 bulb ensuring no light losses due to absorption by painted glass bulbs, ensuring high lumen output, - Full glass construction with no external lacquer coating to peel or scratch off when used outdoors, ensuring long-life colour, - IP54 water/dust/dirt resistant

Technical Assets

Dimensions (mm)

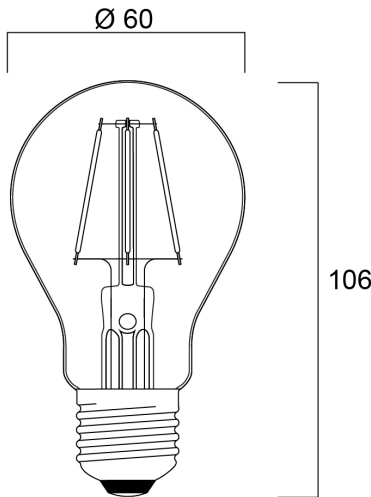

Photometrics

ToLEDo Retro Chroma A60 Green E27 SL

Item No: 0086309



General data

Product name	ToLEDo Retro Chroma A60 Green E27 SL
Technology	LED
Lamp shape	Pear-shape
Cap/Base	E27
Lamp finish	Clear
Fixture rating	Open
General application	SPG
ETIM Class	EC001959
E-number FI	4741156
Warranty	2 years

Optical data

Light colour	Green
Photobiological Risk Group	RG1

Electrical data

Wattage (W)	4
Primary Supply/Product voltage - min (V)	220
Primary Supply/Product voltage - max (V)	240
Control gear required	No
Dimmable	No
Nominal Frequency (Hz)	50/60Hz

Lifetime data

Average life (Rated) (h)	6000
--------------------------	------

Physical data

IP rating	IP54
Nominal Product Height (mm)	106
Nominal Product Diameter (mm)	60
Weight (kg)	0.028

Packaging

Product EAN number	5410288863092
Packaging single length / height (cm)	6.2
Packaging single width (cm)	6.1
Packaging single depth (cm)	11.2
DUN14 (inner)	15410288863099
Units per inner package	6
Packaging inner length / height (cm)	19.6
Packaging inner width (cm)	13.4
Packaging inner depth (cm)	12.2
DUN14 (outer)	25410288863096
Units per outer package	6
Packaging outer length / height (cm)	19.6
Packaging outer width (cm)	13.5
Packaging outer depth (cm)	12.2

Safety data

Breakage cleaning instructions	n/a
Special purpose lamp	Yes
Suitable for household illumination	Yes