


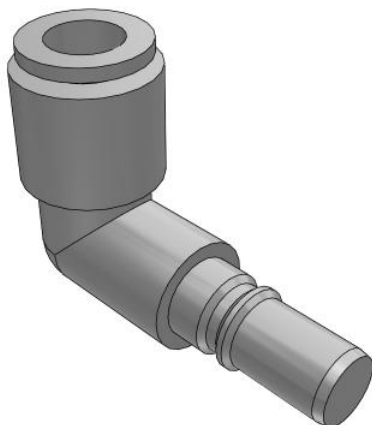

KK*P-*L, S-Couplers, Elbow Type with One-touch Fitting KK3P-08L




Datasheet

- Elbow Type with One-touch Fitting.
- Body size: M5, 1/8, 1/4, 1/2.
- Applicable Tubing O.D.: Ø3.2, Ø4, Ø6, Ø8, Ø10, Ø12, Ø16.

Standard specifications

Body Size	3 (1/8)
Applicable Tubing O.D.	Ø8 mm
-	Air, Water
Maximum operating pressure	1.0 MPa
Minimum operating pressure	-90 kPa
Proof pressure	1.5 MPa
Effective Area	20 mm ²
Sealing principle	Electroless nickel plated (copper-free application), With male thread sealant
Weight	0.012 Kg

Dimensions

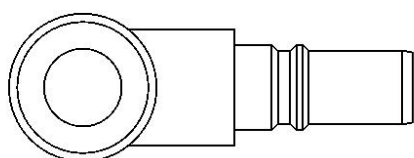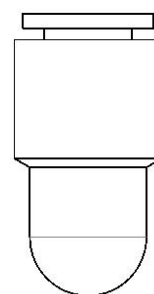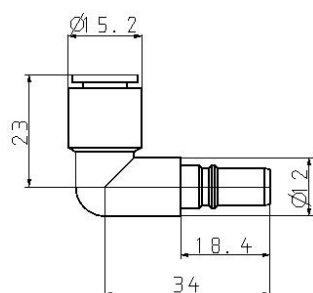

Additional information

Catalogue

[KK-C_EU.pdf](#)