



DIPOLE LTE, ANTENNA MAGNET MOUSE RRDP-W1B7-31530-1M-E-001



■ SPECIFICATION


PARAMETERS	VALUE
Frequency Range	700 MHz ~ 2700 MHz
VSWR, max	2.0
Return Loss	-10 dBi
Radiation	Omni-directional
Impedance	50 Ω
Polarization	Lineal Vertical
Gain	9 dBi
Connector	SMA
Operating Temperature Range	-40 ~ + 70 °C
Storage Temperature Range	-45 ~ +85 °C
Mounting Method	Magnet



DIPOLE LTE, ANTENNA MAGNET MOUSE

RRDP-W1B7-31530-1M-E-001

MECHANICAL SPECIFICATION

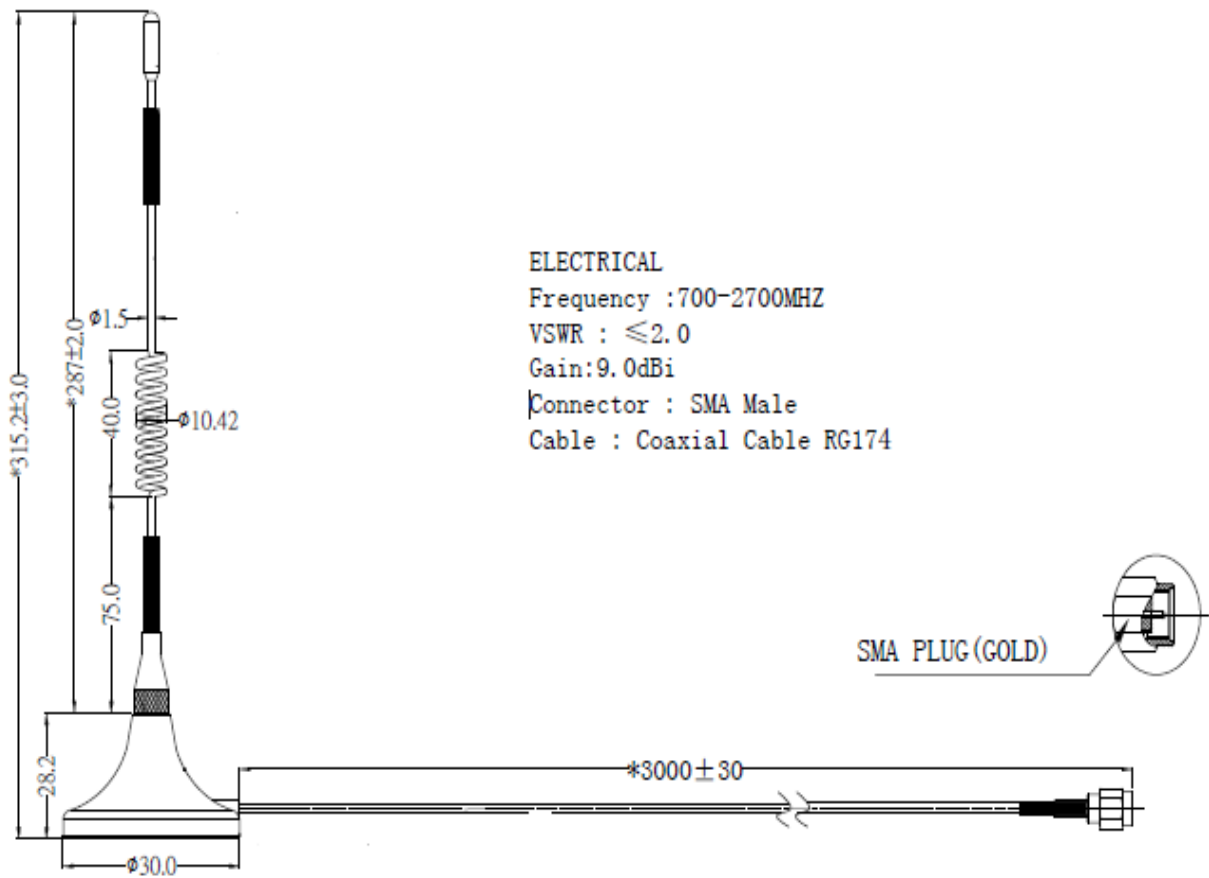




DIPOLE LTE, ANTENNA MAGNET MOUSE

RRDP-W1B7-31530-1M-E-001

FREQUENCY CHARACTERISTICS

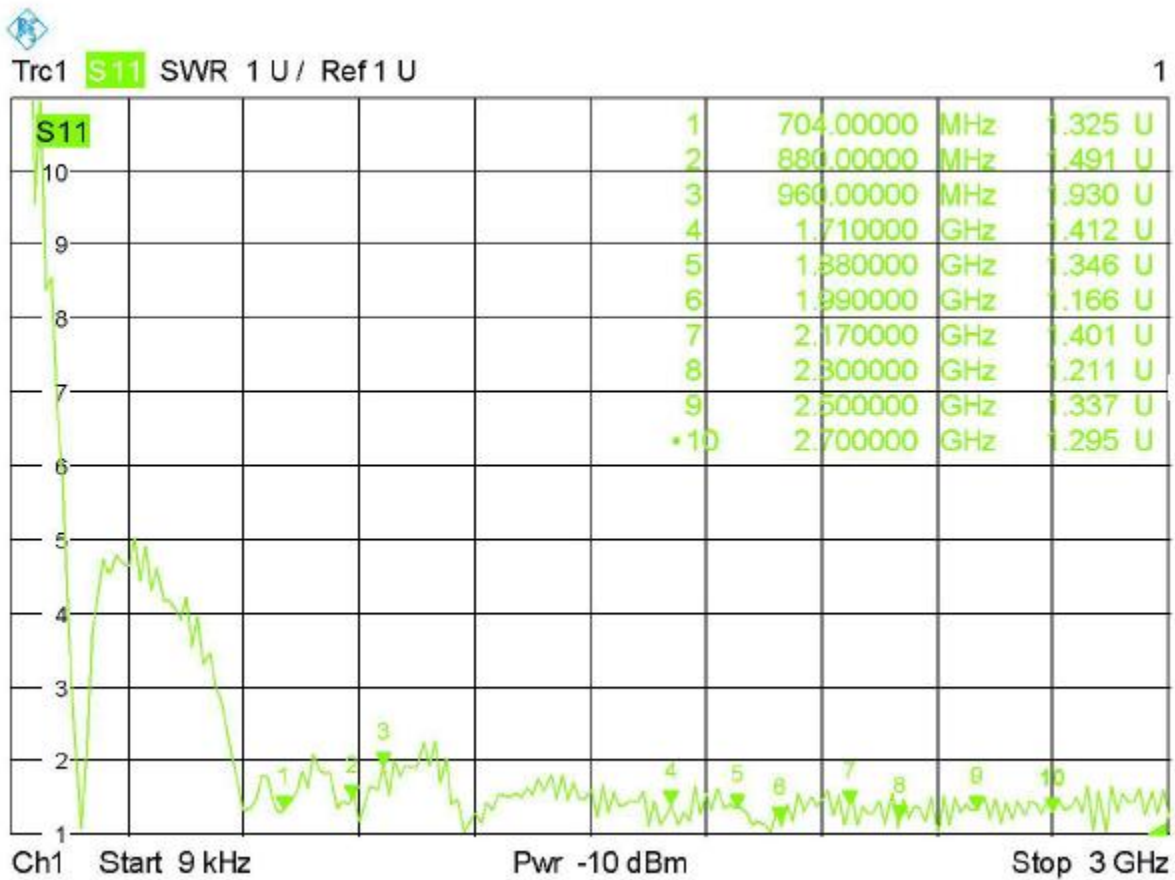

APPROVAL

RS PRO	
DRAWN BY:	AR, May 30, 2018
APPROVED BY:	CP, May 30, 2018
REVISION:	A, Initial Release