


Features

- Thermoresistance PT-1000 Sensor
- Max. operating temperature 200°C
- Protection tube Silicone+Silicone
- Sensor type DIN/EN60751
- Cable type Silicone + Silicone
- Cable Length: 2m

RS PRO Bayonet Type PT-1000 Thermoresistance Temperature Sensor

RS Stock No: 0350373

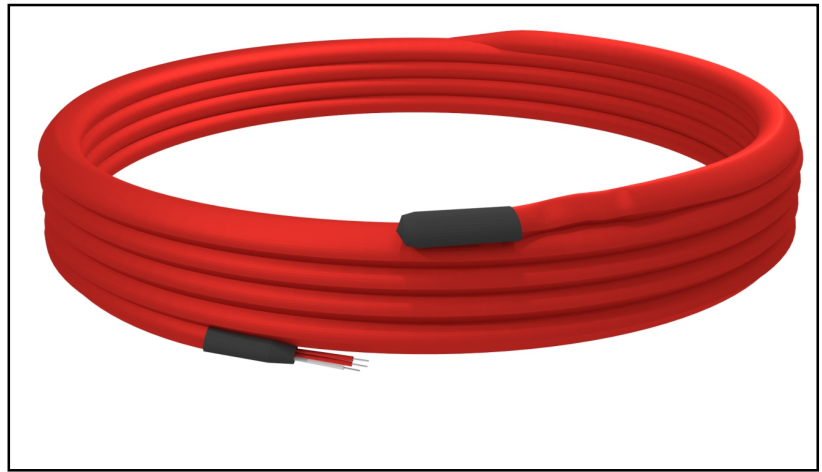

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

Standard Bayonet Type PT1000 Thermoresistance Temperature Sensor

Cable Length(K): 2m

Applications Fields

- Production and Test Equipment
- Food, Chemical, Textile Sectors
- Industrial Control Applications


General Specifications

Max. Operating Temperature	-50 °C / +200 °C
Standard cable types	Silicone + Silicone
Sensor type	DIN/EN60751 Class "B"

Mechanical Specifications

Cable Length (K)	2m
------------------	----

Electrical Connection

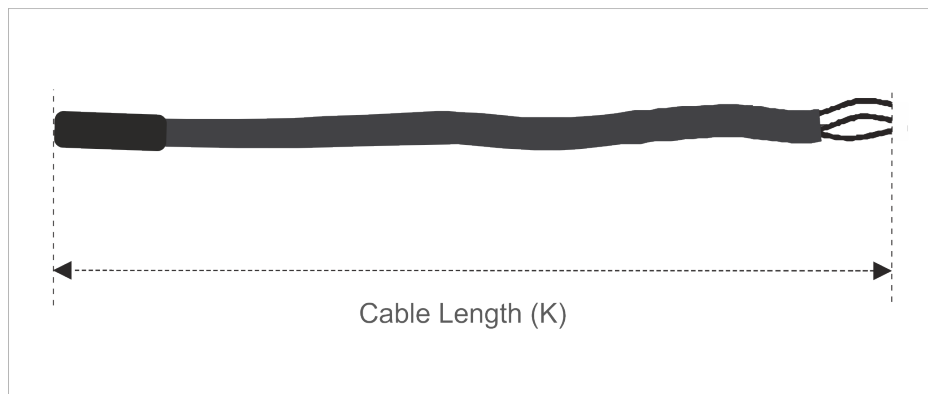

PT-1000 Connections

