




Current inputs			
Primary current I _{pn} (/5)	A		200
Operational frequency			
	min	Hz	50
	max	Hz	60
Secondary output current	A		5
Overload withstand I _{pn}	%		120
Burden			
	cl. 0.5s	VA	2.5
	cl. 0.5	VA	3.75
Insulations			
Rated insulation voltage U _i IEC/EN	V		720
IEC rated short-time thermal current I _{th}	I _{th} for s		40...60
IEC rated dynamic current I _{dyn}	I _{th} for s		2.5
Insulation dry type			Class E
Mechanical features			
Terminals type			Screw
Fixing			DIN rail or by Screw
Weight	g		480
Ambient conditions			
Temperature			
Operating temperature			
	min	°C	-25
	max	°C	+50
Storage temperature			
	min	°C	-40
	max	°C	+80
Relative humidity		%	90
Protection degree			IP30
Dimensions			

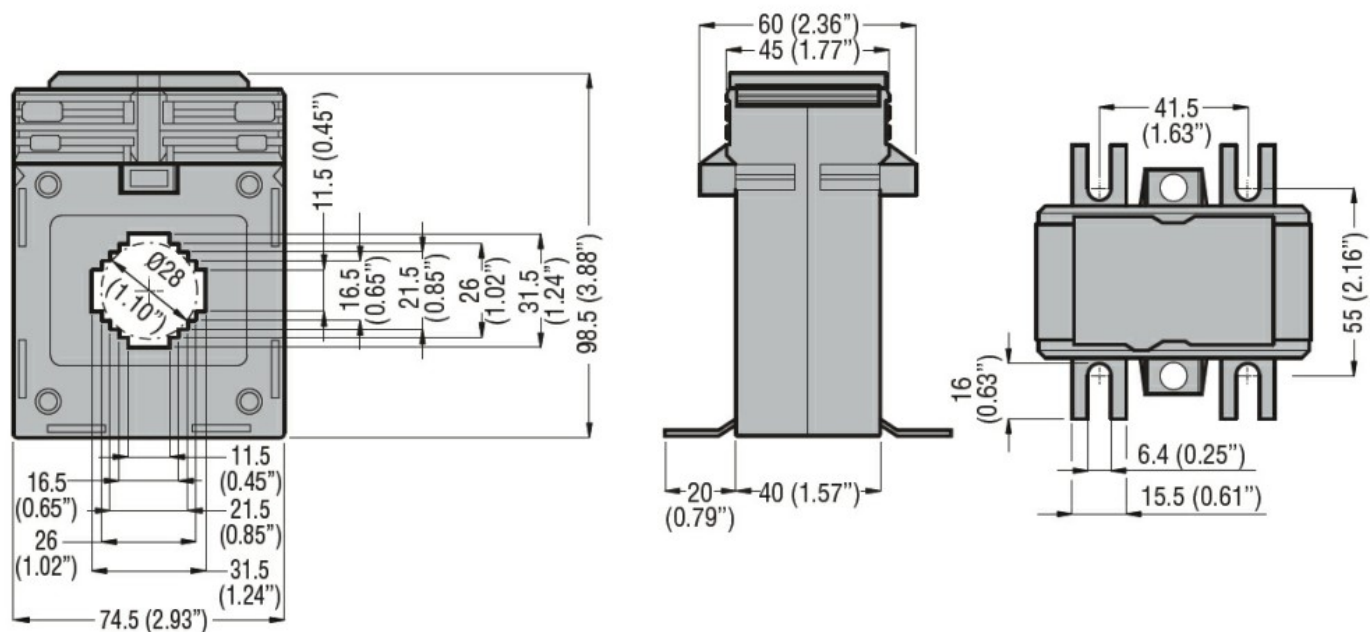

Certifications and compliance

Certifications

IEC/EN/BS 61869-1

IEC/EN/BS 61869-2

Compliance

EAC

ETIM classification

EC000066 - Power contactor, AC switching