

OPTOTRONIC OT DMX 3x1 RGB DIM



Product benefits

- Intelligent electronic constant-voltage 3-channel DMX dimmer
- Compact housing for luminaire installation

Product features

- Three output channels, can be controlled individually via DMX
- Automatic addressing via DIP switches
- Maximum operating output voltage: 1 A per channel
- Control via DMX interface by means of DMX control units
- Reversible protection mechanisms for short-circuits, overtemperature and -loads


Technical data

Electrical data

System wattage	61 W
Nominal voltage	10...24VDC V
Output power	72 W

Dimensions & weight

Length	80.0 mm
Width	40.0 mm
Height	22.0 mm

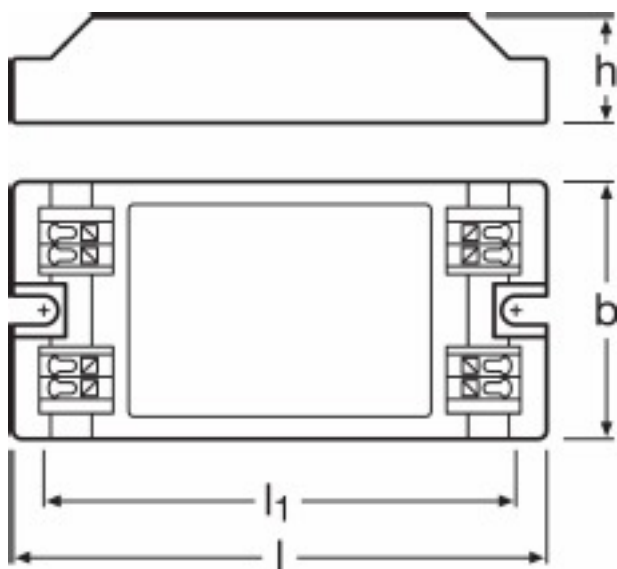

Product line drawing with letters

Temperatures

Ambient temperature range	-20...+50 °C
---------------------------	--------------

Capabilities

Dimming interface	DMX
Type of installation	Luminaire integration/Ceiling integration
Number of control outputs	3

Certificates & standards

Type of protection	IP20
---------------------------	------

Logistical Data

Product code	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Gross weight	Volume
4008321279835	Folding carton box 1	42mm x 25mm x 83mm	44.20g	0.09dm ³
4008321279842	Shipping carton box 10	110mm x 92mm x 129mm	509.80g	1.31dm ³
4008321279859	Shipping carton box 100	0 x 0 x 0		

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.