


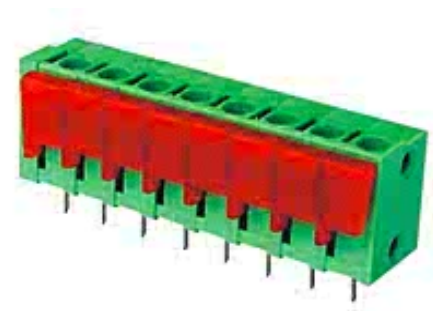

**Part Number :** [397000903](#)  
**Product Description :** 5.00mm Pitch, Eurostyle  
Fixed-Mount Push-Button Terminal Block, Vertical,  
10A, 22-14 AWG, Green, 3 Circuits  
**Series Number :** 39700  
**Status :** Active  
**Product Category :** Terminal Blocks and Barrier  
Strip  
**Engineering Number :** M851-01-1-03-3



## Documents & Resources

### Drawings

[397000903\\_sd.pdf](#)

### 3D Models and Design Files


[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

### [Compliance Statements](#)

- EU RoHS
- REACH SVHC
- Low-Halogen

### [Industry Documents](#)

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

#### Substances of Interest

- PFAS

#### EU RoHS Certificate of Compliance

#### Additional Product Compliance Information

---

## Part Details

### General

Status	Active
Category	Terminal Blocks and Barrier Strip
Series	39700
Description	5.00mm Pitch, Eurostyle Fixed-Mount Push-Button Terminal Block, Vertical, 10A, 22-14 AWG, Green, 3 Circuits
Application	Wire-to-Board
Component Type	One Piece
Product Name	Eurostyle Fixed Mount
Type	PCB Terminal Blocks and Connectors
UPC	78172542641

### Electrical

Current - Maximum per Contact	10.0A
Voltage - Maximum	300V

### Physical

Circuits (Loaded)	3
Circuits (maximum)	3
Color - Resin	Green
Entry Angle	Vertical
Lock to Mating Part	None
Material - Plating Termination	Tin

Material - Resin	Nylon
Number of Rows	1
Orientation	Vertical
Panel Mount	Yes
Pitch - Mating Interface	5.00mm
Polarized to Mating Part	No
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire Size (AWG)	14, 16, 18, 20, 22