


FEATURES

- **Heat Stabilised Nylon:** Provides excellent durability and performance in high-temperature environments up to 105 °C.
- **55 kg Tensile Strength:** Ensures robust and secure bundling of cables and wires.
- **300 mm Length:** Suitable for a wide range of applications, accommodating bundles up to 80 mm in diameter.
- **UL 94 V-2 Fire Behaviour:** Offers a reliable level of flame retardancy for enhanced safety.
- **7.6 mm Width:** Provides additional strength and stability for larger cable bundles.

RS PRO Heat Stabilised Cable Tie, 300 mm Nylon

RS Stock No: 656-022

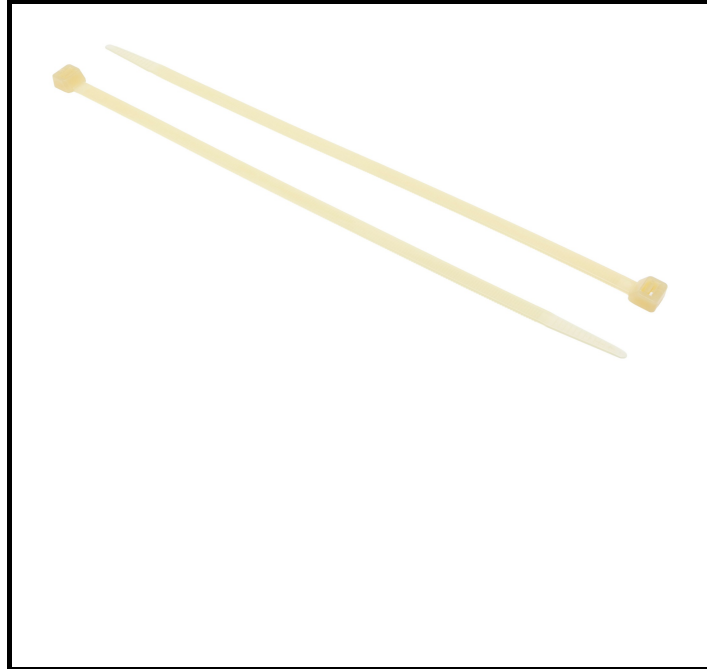

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

The RS PRO Heat Stabilised Cable Tie is designed for secure and reliable bundling of cables and wires. Made from durable nylon, this cable tie is ideal for applications requiring heat resistance and strong tensile strength, ensuring long-lasting performance in demanding environments.

General Specifications

Colour	Light Green
Product Type	Cable Tie
Sub Type	Heat Stabilised
Tensile Strength	55 kg

Protection Category

Fire Behaviour	UL 94 V-2
UV Resistant	No

Mechanical Specifications

Length	300 mm
Material	Nylon
Maximum Bundle Diameter	80 mm
Width	7.6 mm

Operation Environment Specifications

Maximum Operating Temperature	105 °C
-------------------------------	--------

Approvals

Standards/Approvals	ABS 15-TA1338482-PDA, cULus E97527, RoHS, UL94V-2
---------------------	---

