

## Technical data


WS81105

Thrust washer



Needle roller bearing, thrust needle roller bearing, inner ring

### VISUAL (S)

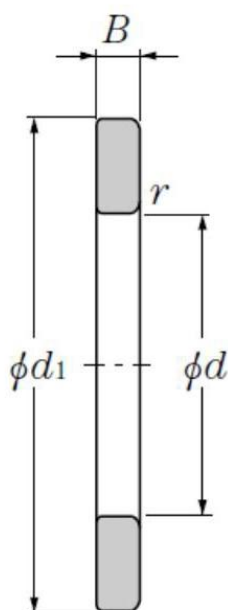

### PRODUCT DEFINITION

|                                                  |          |
|--------------------------------------------------|----------|
| Brand                                            | NTN      |
| d - Bore diameter of support washer IR - WS      | 25 mm    |
| d1 - External diameter of support washer IR - WS | 42 mm    |
| B - Ring thickness                               | 3 mm     |
| rs - Min fillet radius                           | 0,6 mm   |
| Bearing ring (inner ring) WS mass                | 0,021 kg |

### PRODUCT PERFORMANCE

|                                  |        |
|----------------------------------|--------|
| Tmin - Min operating temperature | -20 °C |
|----------------------------------|--------|



**NTN Europe**

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00  
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072  
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

| PRODUCT PERFORMANCE              |                          |
|----------------------------------|--------------------------|
| Tmax - Max operating temperature | 120 °C                   |
| ESHOPDONOTDISPLAY                |                          |
| Tracepart                        | Oui/Yes                  |
| Reference                        | WS81105                  |
| Image                            | NRBWS_1.jpg, NRBWS_3.jpg |

