



SIVACON, side panel / rear panel, Closed, IP40, H: 2200 mm, W: 1000 mm, RAL 7035

Model			
product brand name		SIVACON	
product designation		Side panel/rear panel	
design of the product		Closed	
design of the surface		Powder-coated	
design of the product EMC version		No	
Protection class			
protection class IP		IP40	
Appearance			
RAL color number		RAL 7035	
color		light grey	
Product details			
product component			
• cable entry		No	
• lock		No	
Mechanical Design			
height		2 200 mm	
width		1 000 mm	
depth		1 000 mm	
material		steel	
Approvals Certificates			
General Product Approval		Test Certificates	other



[Special Test Certificate](#)

[Confirmation](#)

[Miscellaneous](#)

other

Environment

[Miscellaneous](#)

Siemens
EcoTech



[Environmental Confirmations](#)

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1200-2UW60-1C>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8MF1200-2UW60-1C>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1200-2UW60-1C

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

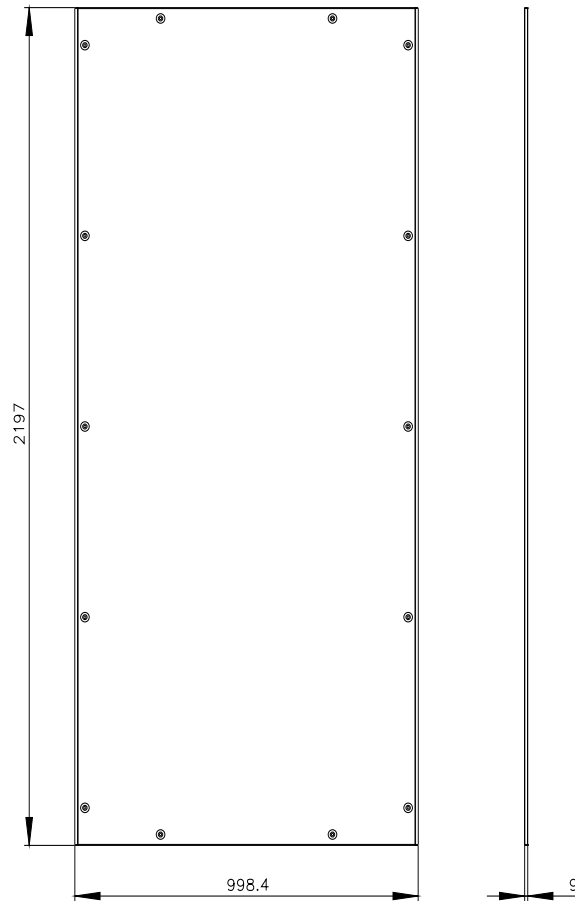

last modified:

4/15/2021 

