



Microminiature Slide Switches

Specifications:


Contact rating:	0.5 A, 12 V DC; 0.3 A, 24 V (AC/DC)
Contact resistance:	< 30 mΩ
Insulation resistance:	> 10 MΩ at 500 V DC
Dielectric strength:	500 V, 50 Hz for the duration of 1 minute
Operating temperature:	-40 °C to +85 °C
Storage temperature:	-40 °C to +85 °C
Mechanical life:	minimum 10 000 operations
Contacts:	brass, gold plated
Terminals:	brass, gold plated
Case:	PA
Soldering conditions:	wave-soldering – max. 5 sec. max. 270 °C

Models

Switching functions

MMP 1010 D – 1

on on

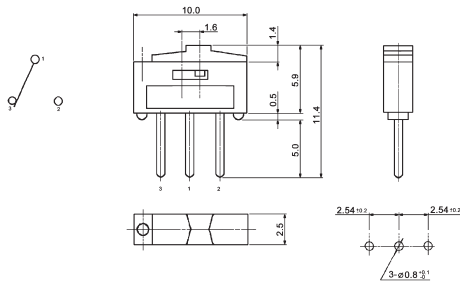

MMP 1010 D-RA – 1

on on

