

FEATURES

- Steel clevis fasteners
- Spring clip
- M12 x 1.75 rod connection thread
- Ball diameter of 12mm
- Overall length of 62mm
- Overall width of 24mm
- Zinc finish for corrosion-resistant finish

RS PRO Steel M12 x 1.75 Clevis, 62mm x 24mm

RS Stock No.: 312-0208



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

These sturdy large-threaded clevis fasteners are U-shaped fasteners with two holes through which a pin is inserted. This lets connected parts rotate about the axis of the pin. For this reason, they're used in various environments, from agriculture and sailing to construction and aviation.

General Specifications


Accessory Type	Ball
Rod Connection Thread	M12 x 1.75
Material	Steel
Finish	Zinc
Applications	Food, medical and petrochemical, automotive and aviation industries

Mechanical Specifications

Overall Length	62mm
Overall Width	24mm
Ball Diameter	12mm

Approvals

Compliance/Certifications	BS970 PE 1 1983 220 MO7, BS970 PE 5 1972 270 A72, DIN 71752
----------------------------------	---

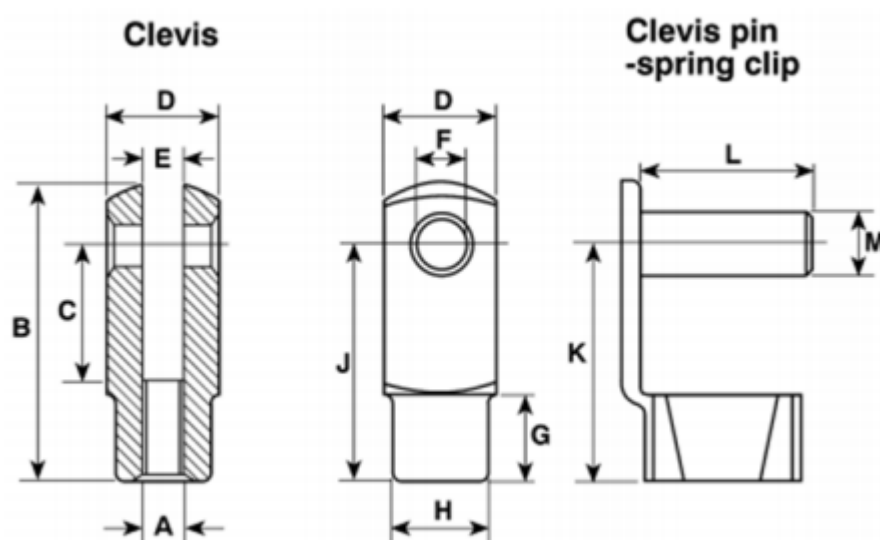

Dimensions (mm)											
Thread A	B	C	D	E	Ø F	G	H	J	K	L	Ø M
M12x1.75	62	24	24	12.15/ 12.33	12	18.0	20	48	47	28	12