



Cast resin joint, Parallel P, 4 x 35mm² to 4 x 185mm²,
L=360mm, 2800 ml, Polyurethane resin (PUR) green
Art.-No. 435-12075 | PAH-3 / SF-PUR-GN | 

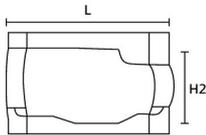


- Colour changes from blue to green whilst mixing
- Impact-proof, transparent moulding shell
- Compact, optimized dimensions
- Longitudinally and transversely watertight
- SF-system
- Joint can be submerged directly after casting
-
-

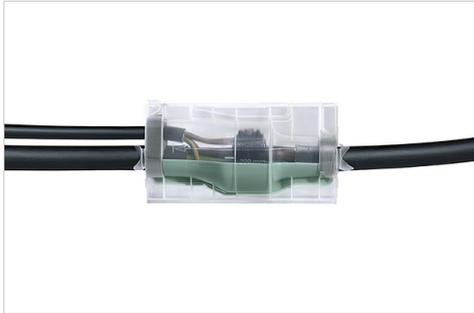

More products in this product group:
[Parallel branch cable joints house connections >](#)

Application	<p>The parallel branch joint PAH is a universal straight-through and branch joint. Suitable as single branch joint with various commercially available branch clamping rings. For polymeric cables and wires made of PVC, XLPE, PE, EPR and utility cables.</p> <p>Application: Especially designed branch joint for building and domestic connections to the low-voltage electrical network. Underground, submerged, outdoor, indoor.</p>
Colour	Green (GN)
Content	<p>Cast resin PUR 33</p> <p>In a two-chamber pouch</p> <p>Transparent moulding shell</p> <p>Foam seal, protective gloves, emery cloth</p> <p>Cleaning cloth, cable kit, installation instructions</p> <p>SF-nozzle (two-chamber pouch)</p>
Material	Polyurethane resin (PUR)
No. of Wires	4
PART DESCRIPTION	PAH-3 / SF-PUR-GN
Pack Content	1 Set
Package Content packed in	set
Product Family	RELICON PAH-3 with PUR 33
Product Group	Parallel branch cable joints house connections
Type	PAH-3 / SF
Variant	Cast resin


Product Dimensions

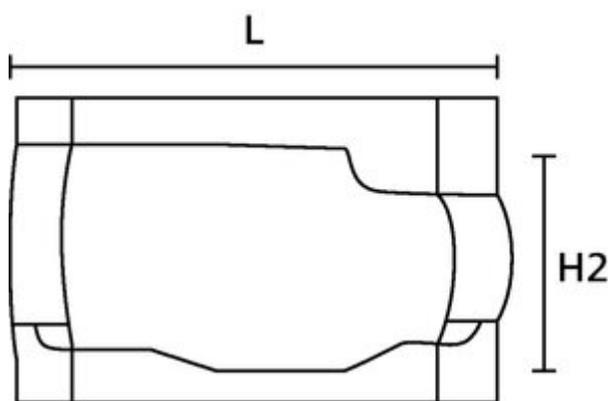

Branch Cable min	4 x 6 mm ²
Branch Cable max	4 x 70 mm ²
Height (H2)	135 mm
Length (L)	360 mm
Main Cable max	4 x 185 mm ²
Main Cable min	4 x 35 mm ²

ELV Compliant (Article 4 - 2)	YES
Halogen-free	No
Hazardous Goods	No
Operating Temperature	-25 °C to +120 °C
ROHS compliant	Yes
Shelf Life	48 months
Specifications	

Logistics and Packaging

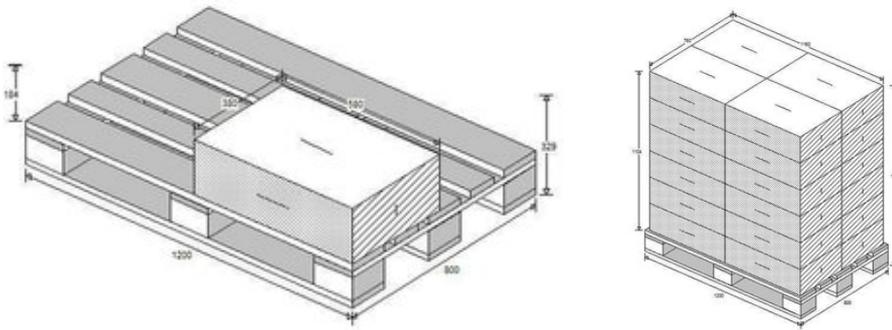

GTIN-13 / EAN	4031026626925
Packaging 3 - Height (m)	0.184 m
Packaging 3 - Length (m)	0.58 m
Packaging 3 - Qty	1
Packaging 3 - Type	box
Packaging 3 - Volume (m ³)	0.0406 m ³
Packaging 3 - Weight (kg)	5.63 kg
Packaging 3 - Width (m)	0.38 m
Packaging 4 - Height (m)	1.095 m
Packaging 4 - Length (m)	1.2 m
Packaging 4 - Qty	20
Packaging 4 - Type	pallet
Packaging 4 - Volume (m ³)	1.051 m ³
Packaging 4 - Weight (kg)	133.6 kg
Packaging 4 - Width (m)	0.8 m
Storage Temperature	+4 °C to +40 °C

More Information

