




Charge 'n' Travel Universal Travel Adapter 70W Dual Cables

PN: 30186, 30187, 30188

Description


- **Advanced GaN III Technology** - The Verbatim Universal Travel Adapter features the latest GaN III technology, a cutting-edge semiconductor material that efficiently handles high voltage and high-frequency applications. This innovation makes the adapter smaller, lighter, and more efficient than traditional silicon-based products.
- **Global Compatibility** - Adapt to over 180 countries with ease. This universal travel adapter ensures you're never without power, allowing you to connect to any local power supply worldwide. Perfect for recharging laptops, smartphones, Bluetooth speakers, tablets, power banks, and more. Simply slide out the three most common international plugs – EU, UK, and US – and rotate the pins for Australia or China sockets.
- **Built-in Dual USB-C Retractable Cables** - Forget about carrying extra cables. The travel adapter includes two retractable USB-C cables compatible with most USB-C devices, ensuring you're always prepared.
- **Superfast 6-in-1 Charging up to 70W** - Charge up to six devices simultaneously with the Verbatim GaN III Universal Travel Adapter. It features an AC power socket, a USA/JP socket, a USB-C ports, a USB-A port, and two retractable USB-C cables, offering a total output of up to 70W. USB-C PD 3.0 and QC 4+ support charging power up to 70W, while USB-A QC 4+ supports up to 60W.
- **Stylish, Compact, and Safe** - Encased in a sleek black 3D diamond design, this adapter is made from high-quality fireproof polycarbonate material and certified by CE, UKCA, FCC, and ROHS. It includes a BS1362 compliant 10A fuse (with a spare) and a travel pouch, providing peace of mind wherever you go.

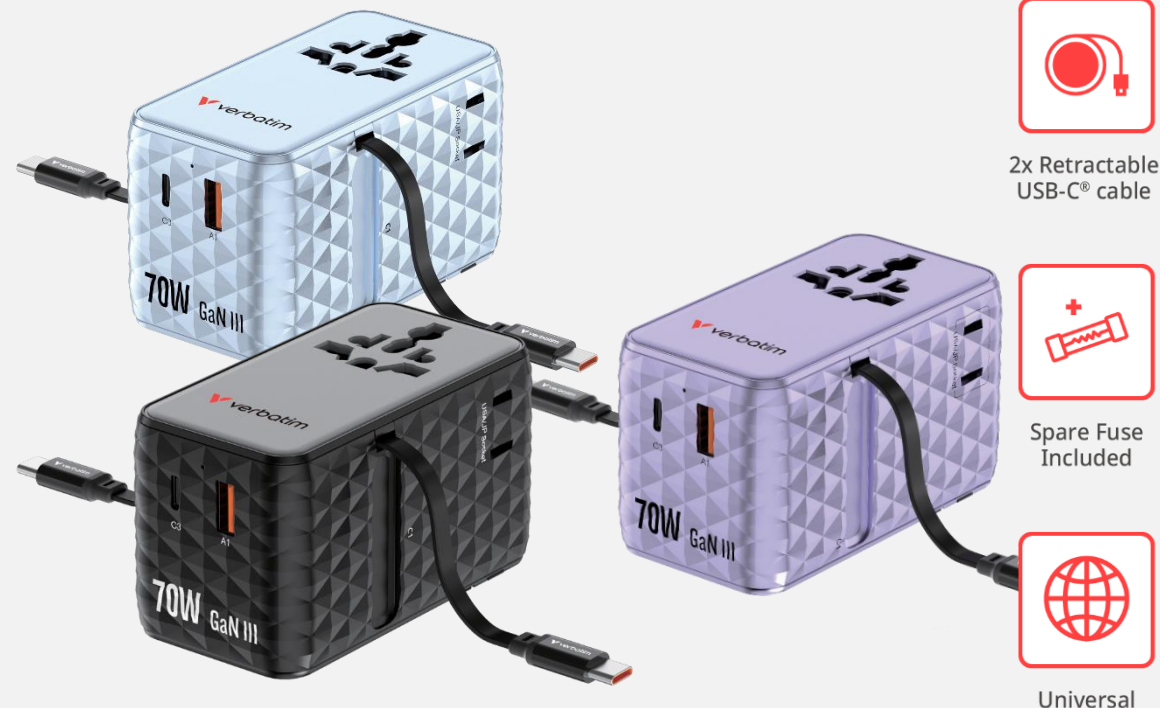

PN: 30186, 30187, 30188

Product Specifications

- Suitable for plugs: Type A / B / C / D / E / F / G / H / I / J / L / N / O
- Suitable for outlets: Type A / B / C / D / E / F / G / H / I / J / K / L / N / O
- AC Input: 100-250 V~, 50/60 Hz, 1.6 A
- Rating: 100-250 V~, 10 A max. 2500 W max.
- USB Single Port Output:
- USB-C1 PD3.0 & QC4+ (PPS Supported): 3.3 – 11 V = 3.3 A, 5 V = 3 A, 9 V = 3 A, 12 V = 3 A, 15 V = 3 A, 20 V = 3.5 A (70 W max.)
- USB-C2 PD3.0 & QC4+ (PPS Supported): 3.3 – 11 V = 3 A, 5 V = 3 A, 9 V = 3 A, 12 V = 3 A, 15 V = 3 A, 20 V = 3 A (60 W max.)
- USB-C3: 5 V = 1 A
- USB-A1 QC3.0: 5 V = 3 A, 9 V = 3 A, 10 V = 2.25 A, 12 V = 3 A, 20 V = 3 A (60 W max.)
- Total DC output: 70 W max.
- Supports PD3.0, QC4+, QC3.0, FCP, AFC, PPS, BC1-2 and more.
- Built-in dual USB-C cable
- Operating Temperature: 0°C ~ +35 °C
- Storage Temperature: -20 °C ~ +85 °C
- Indoor use only! Does not convert voltage! Do not use with appliances requiring ground wire!

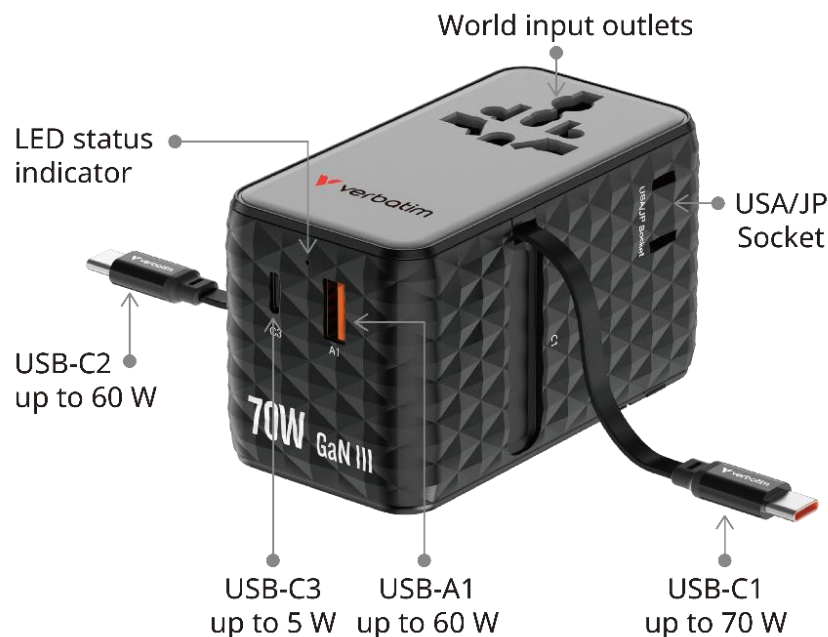

Languages

Front of pack: English (Product description also in French)
Back of pack: English, French, German, Dutch, Italian, Spanish, Portuguese, Polish, Russian, Czech, Hungarian, Serbian, Croatian, Traditional Chinese, Simplified Chinese, Korean, Japanese



Quick Installation Languages

English, German, French, Traditional Chinese + Technical support text in English, French, German, Dutch, Italian, Spanish, Portuguese, Polish, Russian, Czech, Hungarian, Serbian, Croatian, Traditional Chinese, Simplified Chinese, Korean, Japanese

Charge 'n' Travel Universal Travel Adapter 70W Dual Cables



PN	Qty	Colour	Pack Content:
30186	1	Black and Grey	- Verbatim Charge 'n' Travel 70W 2C retractable Universal Travel Adapter - Travel Pouch - Quick Start Guide
30187	1	Blue	
30188	1	Purple	

Charge 'n' Travel Universal Travel Adapter 70W Dual Cables



Reorder No.	Description	Tariff Code	Barcode	EAN-128	EAN-14
30186	Verbatim Charge 'n' Travel 70W 2C retractable Universal Travel Adapter Black	85366900	023942301868	(02)00023942301868(37)20(91)489	50023942301863
30187	Verbatim Charge 'n' Travel 70W 2C retractable Universal Travel Adapter Blue	85366900	023942301875	(02)00023942301875(37)20(91)489	50023942301870
30188	Verbatim Charge 'n' Travel 70W 2C retractable Universal Travel Adapter Purple	85366900	023942301882	(02)00023942301882(37)20(91)489	50023942301887

Reorder No.	30186	30187	30188
Product Dimensions L x W x H	95.8 x 58.2 x 54.3 mm		
Product Weight	285 grams (approx)		
Units per Pack	1		
Pack Dimensions L x W x H	132 x 94 x 58 mm		
Pack Weight	361 grams (approx)		
Units per Inner Carton	N/A		
Inner Carton Dimensions L x W x H	N/A		
Inner Carton Weight	N/A		
Units per Outer Carton	20		
Outer Carton Dimensions L x W x H	300 x 280 x 200 mm		
Outer Cartons Weight	7720 grams (approx)		
Outer Cartons per Layer	12		
Layers per Pallet	7		
Units per Pallet	1680		

