


Features

- Foot Switch made in self-extinguishing UL V0 plastic material
- Free movement of the lever
- Yellow cover and grey base
- Very sturdy and reliable also in harsh environment
- PG16 cable gland

RS PRO Foot Switches

RS Stock No.: 0606331

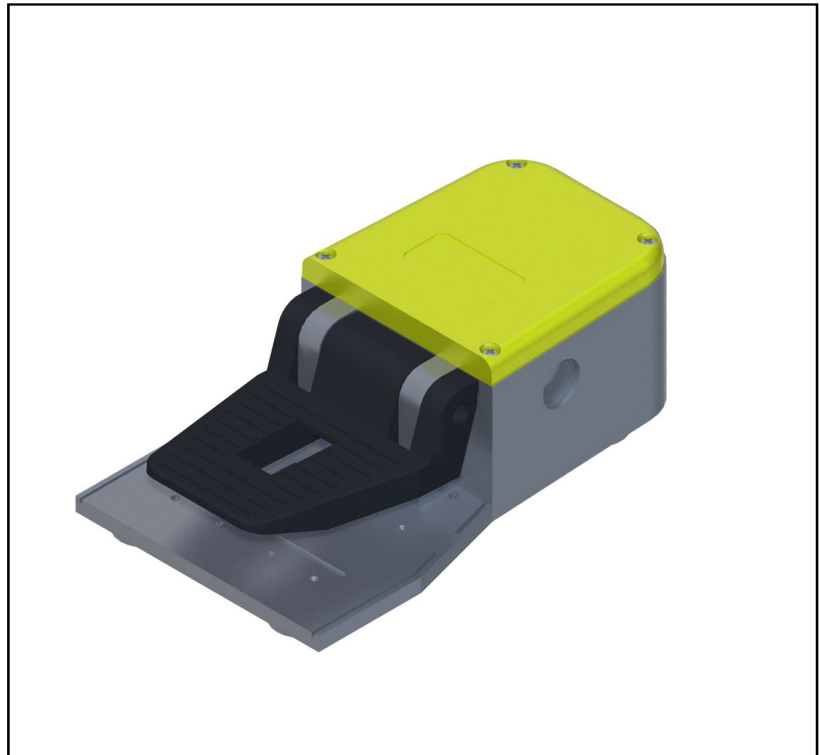

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

Foot switch used to command machineries and equipment in industrial environment. Suited for applications that requires sturdy and reliable products.

General Specifications

Contact Configuration	Contact (1NO+1NC)
Switch Operation	Snap contact
Case Material	Plastic
Switch Environment	Heavy Duty
Contact Material	Ag
Output Type	Analogue
Guard Cover	Yes
Standards Met	IEC 60947-5-1 / EN 60947-5-5
Colour	Yellow
Applications	Foot switches are commonly used in applications where hands-free control is more practical or safer. They can be found on: Industrial machinery and smaller power tools, Hospital beds, Dentist Chairs, Lamps
Cable Connection	Screws with cable clamp plate M3.5 (+, -) pozidriv 2
Accessory Type	Actuator
For Use With	Mechanical operated switch
Mechanical Durability	Mechanical 30000000 Cycles

Electrical Specifications

Contact Voltage Rating (AC)	400V
Contact Voltage Rating (DC)	250V
Contact Current Rating	3A at 400V ac 0.4A at 250V dc
Operating Frequency	3600 operations/hour max. 50-60Hz
Contact Resistance	25mΩ
Overvoltage Category	Class II

Mechanical Specifications

Length	280
Height	85
Dimensions	280x140x85
Width	140

Operation Environment Specifications

Operating Temperature	-25°C to 70°C
-----------------------	---------------

Protection Category

IP Rating	IP65
-----------	------

Approvals

Compliance/Certifications	CE
---------------------------	----