



Connectors > Lighting Connectors > Street Lighting Controls > Street Lighting Connectors



Lighting Product Type: **Connector**
Primary Product Color: **Natural**
Product Height: **24.25 mm**
Lighting Connector Features Included: **Keyed, Not Vented**
Compatible With Agency/Standards Products: **Zhaga**

Features

Product Type Features

Lighting Product Type	Connector
Sealable	Yes

Configuration Features

Lighting Connector Features Included	Keyed, Not Vented
Number of Positions	1

Body Features

Primary Product Color	Natural
-----------------------	---------

Dimensions

Product Diameter	80 mm
Product Height	24.25 mm

Usage Conditions

Operating Temperature Range	-40 – 90 °C[-40 – 194 °F]
-----------------------------	---------------------------

Industry Standards

--	--



IP Rating	IP66
Compatible With Agency/Standards Products	Zhaga

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) SVHC > Threshold: UV-329 (.5% in 10772262383) Article Safe Usage Statements: Wash thoroughly after handling. Do not handle until all safety precautions have been read and understood. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not reviewed for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 2343405-1
MODULE,40MM LUMAWISE
ENDURANCE S. KEYED




TE Part # 2213837-1
ASSEM., 40MM LUMAWISE
ENDURANCE S



Also in the Series

LUMAWISE Endurance S

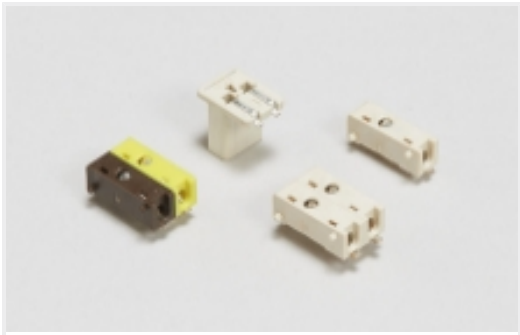

Poke-In Connectors(1)



Street Lighting Connectors(47)




Street Lighting Power Management(5)

Customers Also Bought



TE Part #1-2213871-1
LIGHT CONTROLLER BASE ASSY,
76MM DIA,5POS

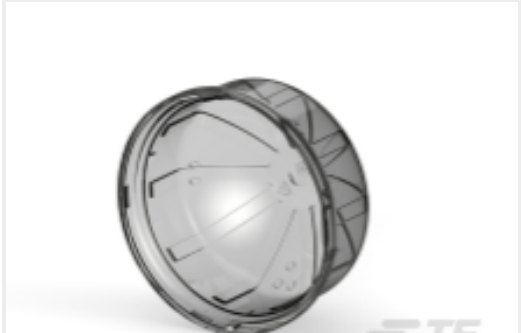


TE Part #2-2328823-2
LUMAWISE S 80MM DIA DOME
SMOKE GRAY MED



TE Part #1-2363638-1
Rcpt, LUMAWISE Endurance S2Kit,
Zhaga,DOT




TE Part #2213831-2
BASE ASSY, 80MM, VENTED, SEALED

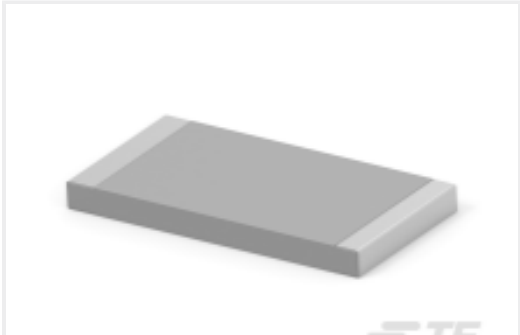

TE Part #2176331-1
CRGP 2512 10R 1%



TE Part #2311664-1
COVER, 76MM DIAMETER, 75MM
HEIGHT

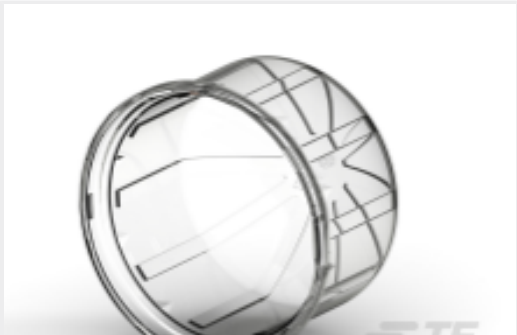

TE Part #1-2328823-3
LUMAWISE S 80MM DIA DOME
CLEAR TALL



TE Part #2213858-1
RECEPTACLE ASSEM., LUMAWISE
ENDURANCE S



TE Part #1-2345834-1
NEW MOTOR CONN REC KIT. PF



TE Part #1-2345832-1
REC. KIT (CONT. NONE) NEW
MOTO. PF

Documents

Product Drawings

LUMAWISE 40MM DIA DOME SMOKE GRAY LOW

English

CAD Files

3D PDF

3D



Customer View Model

[ENG_CVM_CVM_2329013-1_C.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2329013-1_C.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2329013-1_C.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[LUMAWISE ENDURANCE Connector System](#)

English

[LUMAWISE STREET LIGHT DIMMING AND CONTROL QUICK REFERENCE GUIDE](#)

English

[Lumawise Endurance S Modules](#)

English

Product Specifications

[Application Specification](#)

English

Agency Approvals

[UL_EU_CERT_EN_61984_UL_EU_01778_M1_C1](#)

English

[CB_CERT_IEC_61984_US_34131_M1_UL_C1](#)

English

[CB_CERT_US_34131_M1_UL_4788988643_TR_C1](#)

English