



Datasheet


RS PRO Stainless steel variable spring toggle latch,

58mm

Stock number: 1929634

EN

- Stainless steel (304) variable sprung toggle latch
- Complete with catchplate.

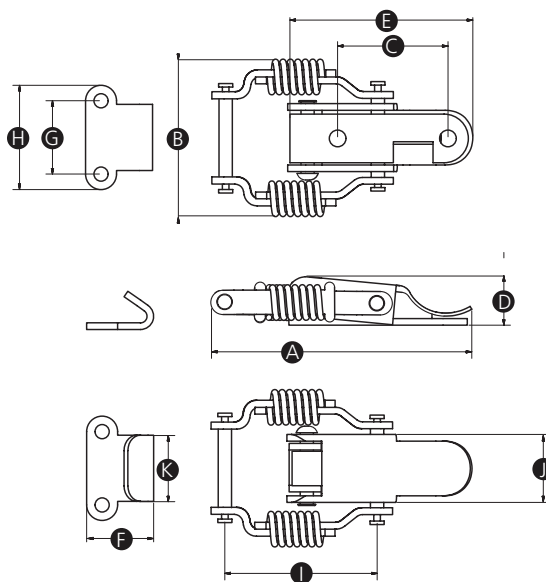

Part No.	A	B	C	D	E	F	G	H	I	J	K	Base hole Size	Hook hole size	Max load (N)
1929634	58	36	13	11	42	15	17	24	35	15	15	4	3	700