 



vacuum suction cup ESV-100-SU

Part number: 191008

FESTO

Wearing part, easily replaceable

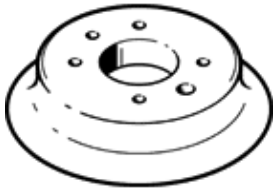

Data sheet

Feature	Value
Min. workpiece radius	460 mm
suction cup diameter	100 mm
suction cup volume	29.779 cm ³
Position of connection	on top
Assembly position	Any
Suction cup shape	round flat
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:-:-]
Food-safe	See Supplementary material information
Ambient temperature	-20 ... 60 °C
Retention force at nominal operating pressure	503.6 N
Product weight	59 g
Colour	blue
Shore hardness	60 +/- 5
Materials note	Free of copper and PTFE Contains PWIS substances Conforms to RoHS
Material suction cup	PUR