


## 21 15 01


## Elbows 45°, PVC-U

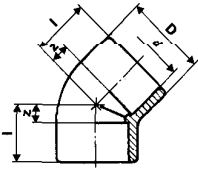

d	PN	Code	£	SP	GP	g	z	D	l
16	16	721.150.105	1.65	10	100	8	4.5	21	18.5
20	16	721.150.106	1.90	10	100	10	5	25	21
25	16	721.150.107	2.00	10	100	18	6	30.5	25
32	16	721.150.108	2.45	10	100	27	8	38.2	30
40	16	721.150.109	3.50	5	50	48	10	47.2	36
50	16	721.150.110	4.40	5	50	86	11.5	58.5	42.5
63	16	721.150.111	6.20	5	50	163	14	73.4	52
75	16	721.150.112	9.75	5	5	250	16.5	87.2	60.5
90	16	721.150.113	14.60	5	5	431	19.5	105	70.5
110	16	721.150.114	30.00	5	5	720	25	127	86
125	16	721.150.115	44.30	1	1	1200	28	146.2	97
140	16	721.150.116	50.90	1	1	1500	32	162	108
160	16	721.150.117	61.90	4	4	2200	36	185	122
200	10	721.150.119	105.20	2	2	3450	43	225.2	149
225	10	721.150.120	141.60	1	1	4900	49	250	168
250	10	721.150.121	174.00	1	1	7150	59.5	282	191.5
280	10	721.150.122	238.00	1	1	10800	66	318	213
315	10	721.150.123	332.00	1	1	14900	74	356	239
400	6	721.150.125	416.00	1	1	23900	93.5	442	301.5

## 21 20 01

## Tees 90° equal, PVC-U

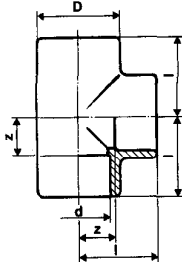

d	PN	Code	£	SP	GP	g	z	D	l
6	16	721.200.101	0.60	10	550	5	4	11	16
8	16	721.200.102	0.60	10	500	5	5	13	17
10	16	721.200.103	0.60	10	350	9	6	16	18
12	16	721.200.104	0.60	10	280	12	7	19	19
16	16	721.200.105	0.97	10	100	10	9	21	23
20	16	721.200.106	1.15	10	100	17	11	25	27
25	16	721.200.107	1.45	10	100	30	14	30.5	33
32	16	721.200.108	2.20	10	100	56	17	38.2	39
40	16	721.200.109	3.10	50	50	100	23	48	49
50	16	721.200.110	4.50	10	10	155	26	58	57
63	16	721.200.111	7.10	10	10	287	33	73	71
75	16	721.200.112	12.20	5	5	480	39	87.2	83
90	16	721.200.113	20.60	5	5	780	46	105	97
110	16	721.200.114	30.20	5	5	1640	58	132.5	119
125	16	721.200.115	58.20	2	2	2400	66	151	135
140	16	721.200.116	79.90	1	1	3260	71	169	147
160	16	721.200.117	105.20	1	1	4889	81	192.5	167
200	10	721.200.119	158.50	1	1	5900	101	225.2	207
225	10	721.200.120	172.50	1	1	9800	114	256	233
250	10	721.200.121	240.00	1	1	12500	137	282	263
280	10	721.200.122	360.00	1	1	18200	147	318	298
315	10	721.200.123	441.00	1	1	24700	167	356	332
400	6	721.200.125	555.00	1	1	39500	212.5	442	420.5