

Illumination element

45-320.1G11

Distribution by
Rs-online



<https://rs-online.eao.com/p/45-320.1G11>

Your product:



45-320.1G11

Illumination element

MOUNTING

Component mounting type: Front mounting

OPERATING-/INDICATION PART

Illumination colour: Yellow

ELECTRICAL CHARACTERISTICS

Operating voltage: 6 / 24 V AC/DC

Surge voltage resistance: 4 kV

Lumi. Intensity: 900 - 1400 mcd

MECHANICAL CHARACTERISTIC

Terminal: Screw terminal

Terminal details 1: Solid 2 x (1.0 ... 1.5mm²)
– With end sleeves 2 x (0.5 ... 0.75 mm²)

Terminal details 2: Finely stranded
– Without end sleeves 2 x (0.5 ... 0.75 mm²)
– Without end sleeves 2 x (0.5 ... 1.5 mm²)
– For AWG cables for auxiliary contacts 2 x (18 ... 14)

Weight: 0.008 kg

CERTIFICATE

REACH: REACH compliant


RoHS: RoHS compliant

OTHER

Short Description:

Illumination element, Screw terminal, Yellow, 6 / 24 V AC/DC, Front mounting

Wiring diagrams:

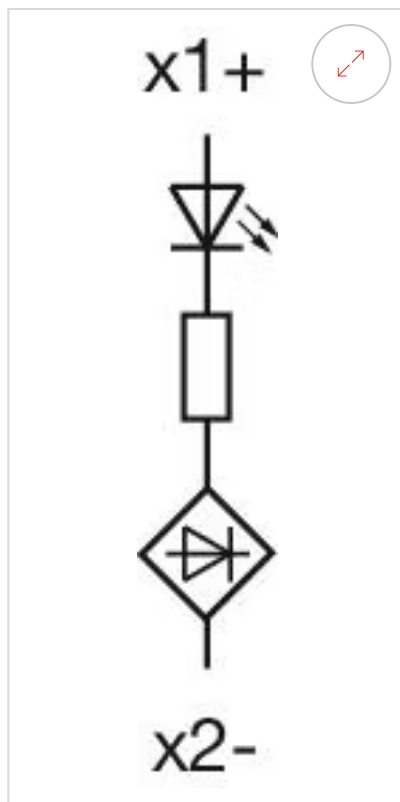

Dimension drawings:

