


clevis foot LN-200

Part number: 9038

FESTO

For swivel mounting of cylinders DNC, DNGU, DNGUT, DNG, DNU, AEVU, ADVU, ADVUP, ADVUP.

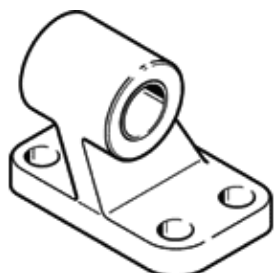

Data sheet

Feature	Value
Size	200
Based on the standard	ISO 15552 (previously also VDMA 24652, ISO 6431, NF E49 003.1, UNI 10290)
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-40 ... 150 °C
Product weight	8,678 g
Materials note	Free of copper and PTFE Conforms to RoHS
Material mounting	Nodular graphite cast iron