


Geberit Mapress Stainless Steel union (FKM, blue)

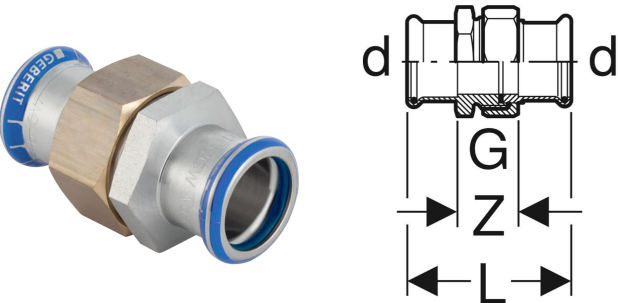

Example image

APPLICATION PURPOSES

- For chemicals and technical liquids
- For district heating water ≤ 140 °C
- For thermal media (solar)
- For mineral and lubricating oil
- For motor fuels (e.g. diesel)
- For compressed air (oil purity class 0–4)

- For solar technology, industry and shipbuilding
- For industrial gases (e.g. acetylene, shielding gases)

CHARACTERISTICS

- Pressing indicator
- Silicone-free (LABS-free)
- Union nut made of brass

- Seal ring made of FKM, blue
- Pressing socket with black protection plug
- Flat gasket made of FPM, green

TECHNICAL DATA

Product material CrNiMo steel 1.4401 (EN 10088)

Art. no.	DN	d, ø mm	G "	L cm	Z cm
50772	12	15	3/4	6.6	2.6
50773	15	18	3/4	6.9	2.9
50774	20	22	1	7.2	3
50775	25	28	1 1/4	7.7	3.1
50776	32	35	1 1/2	8.2	3

Art. no.	DN	d, ø mm	G "	L cm	z cm
50777	40	42	1 3/4	9.5	3.5
50778	50	54	2 3/8	11.3	4.3