


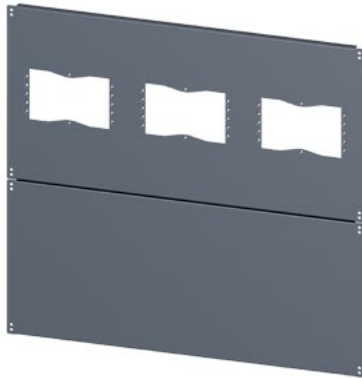

SIVACON, base, with cutouts for flanges, IPXX, T: 1000 mm, W: 1000 mm, zinc-plated

Model	
product brand name	SIVACON
design of the product	With cut-outs for flanges
design of the surface	zinc plated
design of the product EMC version	No
material	steel
protection class IP	IPXX
product component	
• ventilation	No

Mechanical Design	
width	1 000 mm
depth	1 000 mm
net weight	13 900 g

Approvals Certificates		
General Product Approval	Test Certificates	other



[Special Test Certificate](#)

[Confirmation](#)

[Miscellaneous](#)

other	Environment
-------	-------------


[Miscellaneous](#)



[Environmental Confirmations](#)

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
 Information- and Downloadcenter (Catalogs, Brochures,...)
<http://www.siemens.com/lowvoltage/catalogs>
 Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1000-2UB52-0>
 Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/8MF1000-2UB52-0>
 Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)
http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1000-2UB52-0
 CAx-Online-Generator
<http://www.siemens.com/cax>
 Tender specifications
<http://www.siemens.com/specifications>

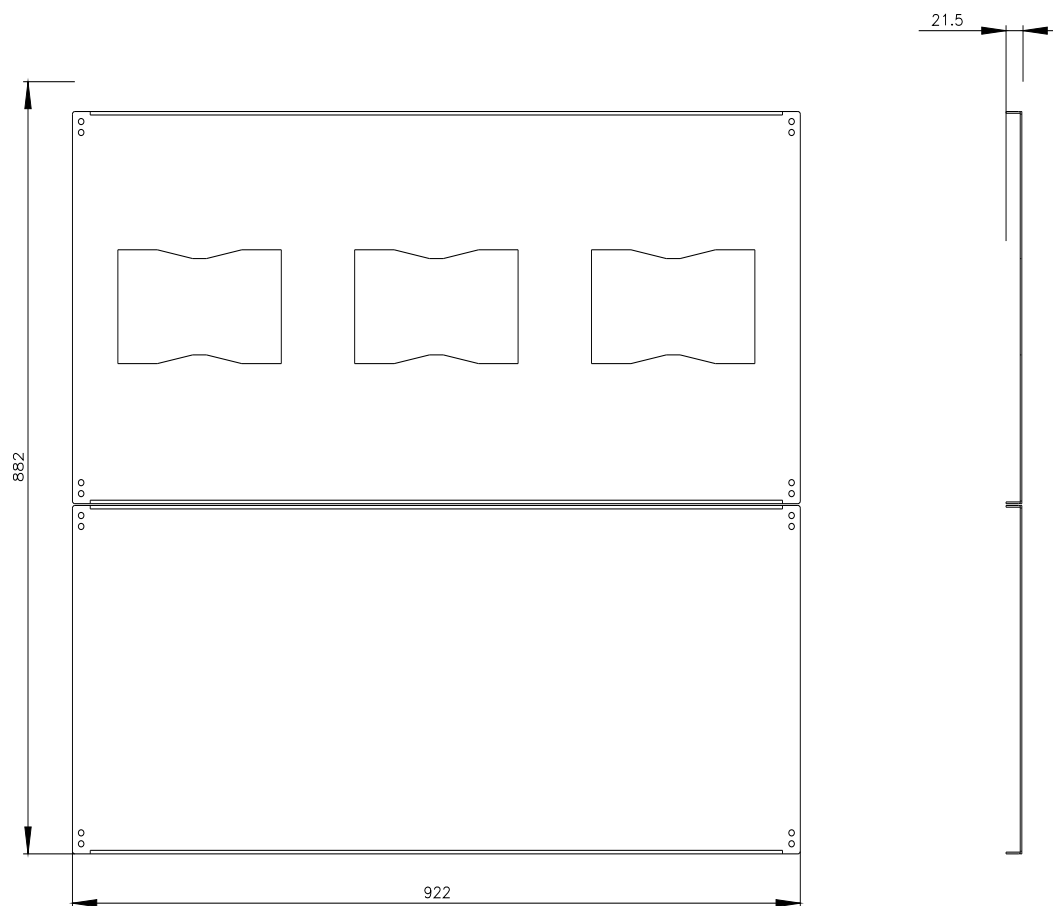

last modified:

6/3/2024 

