

Media module - FL SFP FX SM



2891082

<https://www.phoenixcontact.com/gb/products/2891082>

Please be informed that the data shown in this PDF document is generated from our Online Catalog. Please find the complete data in the user documentation. Our General Terms of Use for Downloads are valid.



The small form-factor plug-in module provides a fiber optic interface with a data transmission speed of 100 Mbps with a wavelength of 1310 nm (long).

Your advantages

- Network structure according to IEC 61850
- IEEE 1613
- MSA compliant

Commercial Data

Item number	2891082
Packing unit	1 pc
Minimum order quantity	1 pc
Sales Key	DNN1ZS
Product Key	DNN1ZS
Catalog Page	Page 332 (C-6-2019)
GTIN	4046356800969
Weight per Piece (including packing)	31 g
Weight per Piece (excluding packing)	16 g
Customs tariff number	85176200
Country of origin	TW

Media module - FL SFP FX SM



2891082

<https://www.phoenixcontact.com/gb/products/2891082>

Technical Data

Dimensions

Width	13.7 mm
Height	8.95 mm
Length	56.5 mm

Material specifications

Housing material	Metal
------------------	-------

Mounting

Mounting type	Insert in SFP slot
---------------	--------------------

Interfaces

Ethernet FO

Connection method	1 LC socket at the SFP module, 100 Mbps
Transmission speed	100 Mbps
Transmission physics	Single-mode fiberglass
Transmission length	typ. 40 km
Wavelength	1310 nm
Signal LEDs	depending on the Factoryline device
No. of channels	1 (LC single mode)

Product properties

Type	Factoryline devices with SFP slot
Product type	SFP module
Format	SFP (Small Form-factor Pluggable)

LED signaling

Status display	via a Factoryline device
----------------	--------------------------

Electrical properties

Transmission medium	Single-mode fiberglass
---------------------	------------------------

Supply

Supply voltage	3.3 V (via Factoryline switch)
Power supply connection	via SFP slot

Ambient conditions

Degree of protection	IP20
Ambient temperature (operation)	-40 °C ... 85 °C (non-condensing)
Ambient temperature (storage/transport)	-40 °C ... 85 °C (non-condensing)
Permissible humidity (operation)	30 % ... 95 % (non-condensing)
Permissible humidity (storage/transport)	30 % ... 95 % (non-condensing)

Media module - FL SFP FX SM



2891082

<https://www.phoenixcontact.com/gb/products/2891082>

Vibration (operation)	in acc. with IEC 60068-2-6: 5g, 150 Hz
Air pressure (operation)	86 kPa ... 108 kPa (1500 m above sea level)
Air pressure (storage/transport)	66 kPa ... 108 kPa (3500 m above sea level)

Media module - FL SFP FX SM



2891082

<https://www.phoenixcontact.com/gb/products/2891082>

Approvals



DNV GL

Approval ID: TAA00000YV



LR

Approval ID: LR22250919TA



NK

Approval ID: TA19464M



BV

Approval ID: 48146/A1 BV

BSH

Approval ID: Nr. 966



RINA

Approval ID: ELE162721XG

ABS

Approval ID: 21-2066186-PDA

Media module - FL SFP FX SM



2891082

<https://www.phoenixcontact.com/gb/products/2891082>

Classifications

ECLASS

ECLASS-9.0	19179290
ECLASS-10.0.1	19179290
ECLASS-11.0	19179090

ETIM

ETIM 8.0	EC000310
----------	----------

UNSPSC

UNSPSC 21.0	43222600
-------------	----------

Media module - FL SFP FX SM



2891082

<https://www.phoenixcontact.com/gb/products/2891082>

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
China RoHS	Environmentally Friendly Use Period = 10;
	For information on hazardous substances, refer to the manufacturer's declaration available under "Downloads"

Media module - FL SFP FX SM

2891082

<https://www.phoenixcontact.com/gb/products/2891082>


Accessories

FO patch cable

FO patch cable - FOC-SC:PA-SC:PA-OS2:D01/1 - 1115550

<https://www.phoenixcontact.com/gb/products/1115550>

Single-mode OS2 duplex jumper, SC-SC, UPC polishing, length 1 m

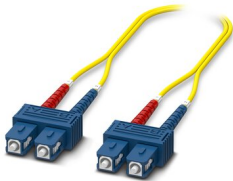


FO patch cable

FO patch cable - FOC-SC:PA-SC:PA-OS2:D01/2 - 1115548

<https://www.phoenixcontact.com/gb/products/1115548>

Single-mode OS2 duplex jumper, SC-SC, UPC polishing, length 2 m

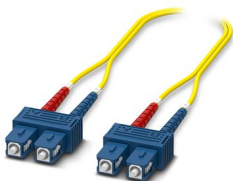

Media module - FL SFP FX SM

2891082


<https://www.phoenixcontact.com/gb/products/2891082>

FO patch cable

FO patch cable - FOC-ST:PA-SC:PA-OS2:D01/1 - 1115582

<https://www.phoenixcontact.com/gb/products/1115582>

Single-mode OS2 duplex jumper, ST-SC, UPC polishing, length 1 m

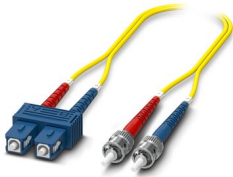


FO patch cable

FO patch cable - FOC-ST:PA-SC:PA-OS2:D01/2 - 1115581

<https://www.phoenixcontact.com/gb/products/1115581>

Single-mode OS2 duplex jumper, ST-SC, UPC polishing, length 2 m

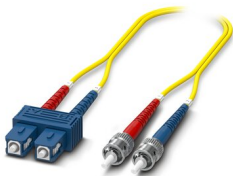

Media module - FL SFP FX SM

2891082


<https://www.phoenixcontact.com/gb/products/2891082>

FO patch cable

FO patch cable - FOC-LC:PA-SC:PA-OS2:D01/1 - 1115618

<https://www.phoenixcontact.com/gb/products/1115618>

Single-mode OS2 duplex jumper, LC-SC, UPC polishing, length 1 m

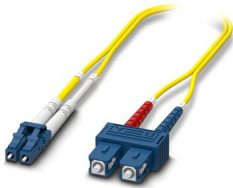


FO patch cable

FO patch cable - FOC-LC:PA-SC:PA-OS2:D01/2 - 1115617

<https://www.phoenixcontact.com/gb/products/1115617>

Single-mode OS2 duplex jumper, LC-SC, UPC polishing, length 2 m

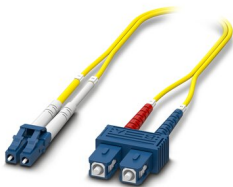

Phoenix Contact 2022 © - all rights reserved
<https://www.phoenixcontact.com>

PHOENIX CONTACT Ltd
Halesfield 13, Telford
Shropshire, TF7 4PG
01952 681700
info@phoenixcontact.co.uk