

L 58 W/76

OSRAM NATURA T8 | Tubular fluorescent lamps 26 mm, with G13 bases, for food presentation



Areas of application

- Bakeries, meat processors, butchers
- Shops
- Supermarkets and department stores
- Especially suitable for the food sector (DIN 10504)

Product benefits

- Specially tailored spectral distribution
- Food looks fresh and appetizing without unduly "beautifying" it

Product features

- Average lifetime: 20,000 h with preheat ECG



Technical data


Electrical data

Nominal wattage	58.00 W
Rated lamp efficacy (HF data 25 °C)	Under clarification by authority and standardization body
Rated wattage	58.00 W

Photometrical data

Luminous flux at 25 °C	2850 lm
Light color	76
Light color as per EN 12464-1	NATURA
Color coordinates chromaticity diagram	0.379/0.314

Dimensions & weight

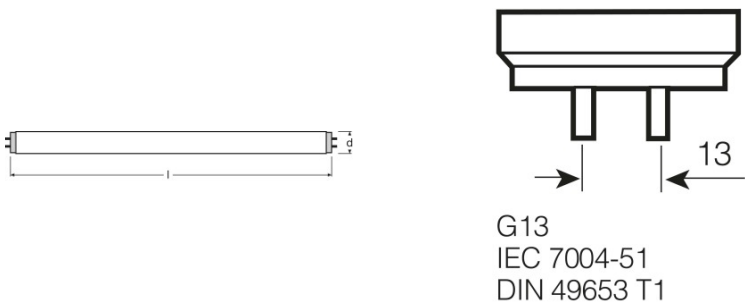

Tube diameter	26 mm
Length	1500.0 mm
Length with base excl. base pins/connection	1500.00 mm
Diameter	26.0 mm

Lifespan

Service life	18000 h ¹⁾
Lifespan	20000 h ¹⁾
Rated lamp life time	20000 h
Nominal lamp life time	20000 h

¹⁾ With preheat ECG

Additional product data

Base (standard designation)	G13
Lamp mercury content	4.5 mg


Product datasheet

Appropriate disposal acc. to WEEE	Yes
-----------------------------------	-----

Certificates & standards

Energy efficiency class	B
Energy consumption	69 kWh/1000h

Light Distribution

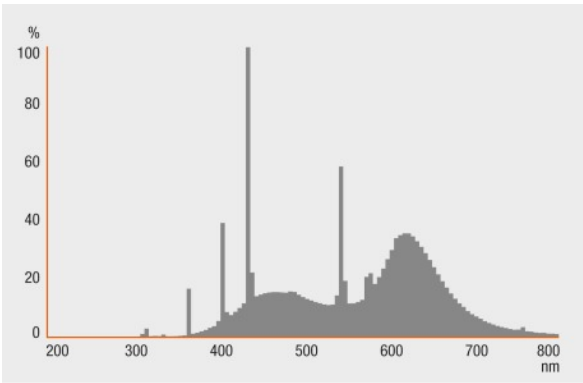

Spectral power distribution




Guarantee

Product datasheet

Safety advice

In case of lamp breakage: www.osram.com/brokenlamp

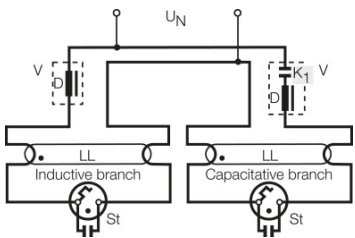

Circuit diagram

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Volume	Gross weight
4008321205407	L 58 W/76	Shipping carton box 10	145 mm x 62 mm x 1542 mm	13.86 dm ³	2704.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

References / Links

For more information on QUICKTRONIC electronic control gear go to
▶ www.osram.com/QUICKTRONIC

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.