



Wire Marking and Identifying

- **Dispensers** pg. 160
- **Books** pg. 165
- **Computerized Systems** pg. 168

ScotchCode™ identification systems give you dozens of ways to mark your product. The line from 3M includes dispensers, preprinted alphanumeric and colored tape, write-on books and tags, and computerized systems of markers. You have the choice of pressure-sensitive adhesive or self-laminating adhesive — whichever is best for your needs. Use these products for marking wire and cable of all diameters, distribution panels, repair and replacement parts, wires and hoses in motorized vehicles, terminal strips, motor leads, sub-motor leads, sub-assembly leads, control panels and much more.



3M™ ScotchCode™ Self-Laminating Wire Markers

48

✓ Features — Advantages — Benefits

3M™ ScotchCode Wire Marking and Identifying Products

Preprinted wire markers	Easy to read	Easy to use
Write-on wire markers	Convenient customization	Saves money
Wire marker tags	Easily removed or repositioned	Saves time
Self-laminating markers	Stay in place	Reduces worry
Adhesive marker	Long term	Security

? Frequently Asked Questions

- How will I know if the STD dispenser is pre-filled or empty?** STD is empty; STD-C and STD-0-9 are pre-filled.
- Which product do I use for high volume marking?** SCS-AM Computer Sheets.
- Which dispensers come empty?** STD is empty.
- What is the tape width on the STD rolls?** 0.215 inches.
- What are the number of digits on the rolls?** There are 576 digits per roll.

Dispensers

3M™ ScotchCode™ STD-TAG Dispenser


The patented ScotchCode STD-TAG Dispenser simplifies the process of permanently or temporarily marking wires with ScotchCode wire marker tags. The dispenser allows easy printing of the tag with a permanent marking pen. A built-in blade quickly and neatly cuts the marker. The dispenser also provides a handy platform on which to write, something that's not always readily available in the field.

The STD-TAG dispenser is refillable and designed to hold two cartridges of STD wire marking tags (two different sizes), as well as a ScotchCode SMP Permanent Marking Pen. The tool is rugged and compact. The tags are available in two sizes, STD-101 and STD-102. Applications for both types of tags include identifying wire, cable conduit and tubing, as well as bundling wire, cable or any other objects with a circumference which can be handled with a miniature or standard width cable tie.



49

Specifications and Ordering Information for 3M ScotchCode STD-TAG Dispenser

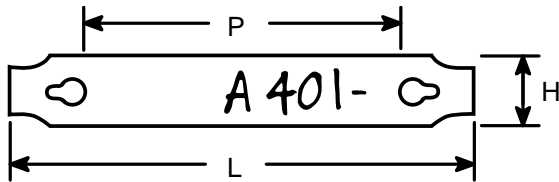

Product Number	UPC (054007-)	Labels Per Roll	Write-On Area		Marker Size		Recommended Wire Size	Min. Order Case Qty.
			P	H	L	H		
STD-TAG	50345	—	—	—	—	—	—	10*
STD-101	50346	50	1.53" (9,53 mm)	0.375" (61,0 mm)	2.40" (60,96 mm)	0.375" (9,53 mm)	18–10 AWG (0,75–4,0 mm ²)	10 (0,5–1,5 mm ²)
STD-102	50347	75	0.86" (21,84 mm)	0.250" (6,35 mm)	1.60" (40,6 mm)	0.250" (6,35 mm)	22–14 AWG (0,5–1,5 mm ²)	10 (0,5–1,5 mm ²)
SMP Marker Pen	09963	—	—	—	—	—	—	50

* This case quantity is 10 sets of: 1 STD-TAG, 1 STD-101, 1 STD-102, and 1 SMP pen.

3M™ ScotchCode™ Write-On Dispensers



These three self-laminating, write-on marker dispensers are handy for identifying wire and cable as well as household, automotive, plumbing and sporting equipment.


They are easy to use, refillable and come with an SMP permanent marking

Applications:

- **Home use:** VCRs, TVs, cable, stereo components, phones, computers, luggage, satellite installation
- **Do-It-Yourself Home Improvements:** home security, sprinkler systems, sound systems, exterior lighting design
- **Automotive:** plugs, hoses, spark plugs, stereos, car alarms
- **Plumbing:** pipes, hoses, tubes, parts, vents
- **Sporting Equipment:** golf clubs, camping equipment, bags, bats, fishing rods, rackets, bicycles
- **Equipment Identification:** hand and power tools

pen. The dispensers' design provides convenience and protects the die-cut adhesive markers.

Specifications and Ordering Information for ScotchCode Write-On Dispensers

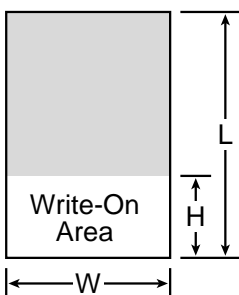


Product Number	UPC (054007-)	Description	Labels Per Roll	Write-On Area		Marker Size		Recommended Wire O.D.	Inner Unit Pack	Min. Order Case Qty.
				W	H	W	L			
SLS	49653	Largest dispenser with tape and SMP pen	170	1" (25 mm)	0.5" (13 mm)	1" (25 mm)	2.312" (58 mm)	0.15 - 0.49" (3,8 - 12,4 mm)	1/card	10
SLS-R	49652	Refill roll for SLS	170	1" (25 mm)	0.5" (13 mm)	1" (25 mm)	2.312" (58 mm)	0.15 - 0.49" (3,8 - 12,4 mm)	1/card	10
SLW	12177	Larger dispenser with tape and SMP pen	70	1" (25 mm)	0.75" (19 mm)	1" (25 mm)	5" (127 mm)	0.23 - 1.32" (5,8 - 35,5 mm)	1/card	10
SLW-R	49651	Refill roll SLW	70	1" (25 mm)	0.75" (19 mm)	1" (25 mm)	5" (127 mm)	0.23 - 1.32" (5,8 - 35,5 mm)	1/card	10
SWD	11954	Regular dispenser with tape and SMP pen	250	0.75" (19 mm)	0.312" (8 mm)	0.75" (19 mm)	1.375" (35 mm)	0.09 - 0.31" (2,3 - 7,8 mm)	1/card	10
SWD-R	12201	Refill roll for SWD	250	0.75" (19 mm)	0.312" (8 mm)	0.75" (19 mm)	1.375" (35 mm)	0.09 - 0.31" (2,3 - 7,8 mm)	1/card	10



Features — Advantages — Benefits

3M ScotchCode Write-On Dispensers

Ergonomically designed	Markers dispense easily	Easy to use
Pens and refill rolls sold separately	Reusable	Saves money
Die-cut markers now in small, medium and large	Provides a variety of uses	Increases productivity
Resists dirt, oil, heat and moisture	Markers stay clean & dry	Improves quality
Transparent overwrap with self-laminating, pressure-sensitive adhesive	Protects printing	Improves quality

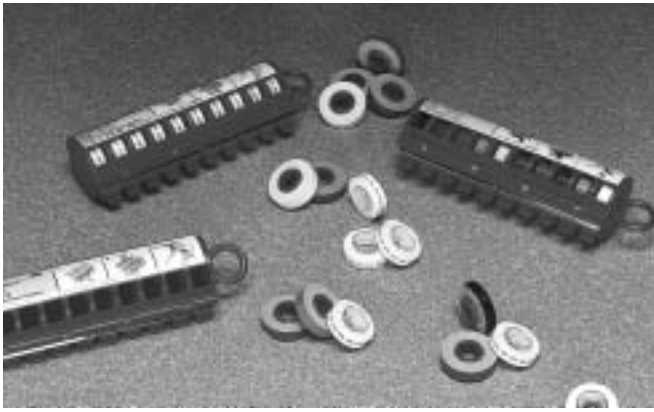3M™ ScotchCode™ STD Tape Dispenser

51

The ScotchCode STD Tape Dispenser is a compact, carry-along dispenser with ten refillable compartments that hold eight-foot rolls of non-smear polyester tape. Used for marking binder groups, wire or cable, the tapes' high tack, acrylic adhesive resists solvents, oil and water, and adheres firmly to insulation surfaces. An end-loop hooks the dispenser easily to a tool pouch or belt. Dispensers can be ordered empty or filled with 10 rolls of either pre-printed numbers 0-9 or NEMA colors.

ScotchCode SDR Dispenser Refill Rolls

This aggressive adhesive system, combined with the flexible polyester film backing, provides a thin, conformable tape that is durable, and will hold up in most industrial electrical applications. The smooth surface of this tape allows dirt and grime to be easily wiped off, providing text legibility even after extended exposure to a build-up of contamination. ScotchCode SDR Wire Marking Tape is available in ten NEMA colors, individual numbers and consecutive numbers.

The SDR tape can be used for the following applications involving operating temperatures ranging from -40°F to 250°F (-40°C to 121°C):

- Marking all types of wire and cable including power, control, fiber optic, electronic, telecommunications and instrumentation
- Phase identification on large or small gauge wire or cable
- Identification of terminal blocks, terminal strips, and wire in panel boards or a piece of switchgear
- Automotive applications on tubing, hoses and replacement parts

Specifications and Ordering Information for ScotchCode Wire Marker Tape Dispensers

Product Number	UPC (054007-)	Description	Minimum Order Case Qty.
STD	12172	Dispenser only—holds 10 rolls	25
STD-X	49519	Dispenser only—holds 10 rolls	10
STD-0-9	12174	Dispenser filled with 10 rolls of numbered tape (one each of 0-9)	25
STD-0-9X	49518	Dispenser filled with 10 rolls of numbered tape (one each of 0-9)	10
STD-C	12175	Dispenser filled with 10 rolls of colored tape (one each of black, blue, brown, green, gray, orange, red, violet, white and yellow)	25
STD-CX	49517	Dispenser filled with 10 rolls of colored tape (one each of black, blue, brown, green, gray, orange, red, violet, white and yellow)	10

**Features — Advantages — Benefits****ScotchCode STD Wire Marker Tape Dispenser**

Compact Design	Easy to handle	Easy to use
Hangs from a tool belt	Convenient	Easy to use
Provides contamination protection around the wire markers	Markers stay clean & dry	Improves quality
Can be custom filled to meet specific project requirements	No waste	Saves money
Dispenses only the desired length	Prevents waste	Saves money
Holds ten rolls of SDR wire marking tape	Compact	Increases productivity

Specifications and Ordering Information for ScotchCode™ SDR Wire Marker Tape (refills)

Product Number	UPC (054007-)	Description	Inner Unit Pack	Case Qty.
SDR-0	09369	0	10/box	50
SDR-1	09370	1	10/box	50
SDR-2	09371	2	10/box	50
SDR-3	09372	3	10/box	50
SDR-4	09373	4	10/box	50
SDR-5	09374	5	10/box	50
SDR-6	09375	6	10/box	50
SDR-7	09376	7	10/box	50
SDR-8	09377	8	10/box	50
SDR-9	09378	9	10/box	50
SDR-0-9	09368	Consecutive 0-9	10 rls/pk	50 rolls or 5 packs
SDR 10-19	09379	Consecutive 10-19	10 rls/pk	50 rolls or 5 packs
SDR 20-29	09380	Consecutive 20-29	10 rls/pk	50 rolls or 5 packs
SDR 30-39	09381	Consecutive 30-39	10 rls/pk	50 rolls or 5 packs
SDR 40-49	09382	Consecutive 40-49	10 rls/pk	50 rolls or 5 packs
SDR 50-59	09383	Consecutive 50-59	10 rls/pk	50 rolls or 5 packs
SDR 60-69	09384	Consecutive 60-69	10 rls/pk	50 rolls or 5 packs
SDR 70-79	09385	Consecutive 70-79	10 rls/pk	50 rolls or 5 packs
SDR 80-89	09386	Consecutive 80-89	10 rls/pk	50 rolls or 5 packs
SDR 90-99	09387	Consecutive 90-99	10 rls/pk	50 rolls or 5 packs
SDR-A	09388	A	10/box	50
SDR-B	09389	B	10/box	50
SDR-C	09390	C	10/box	50
SDR-D	09391	D	10/box	50
SDR-E	09392	E	10/box	50
SDR-F	09393	F	10/box	50
SDR-G	09394	G	10/box	50
SDR-H	09395	H	10/box	50
SDR-I	09396	I	10/box	50
SDR-J	09397	J	10/box	50
SDR-K	09398	K	10/box	50
SDR-L	09399	L	10/box	50
SDR-M	09403	M	10/box	50
SDR-N	09405	N	10/box	50
SDR-O	09406	O	10/box	50
SDR-P	09407	P	10/box	50
SDR-Q	09408	Q	10/box	50
SDR-R	09409	R	10/box	50
SDR-S	09410	S	10/box	50
SDR-T	09411	T	10/box	50
SDR-U	09415	U	10/box	50
SDR-V	09416	V	10/box	50
SDR-W	09417	W	10/box	50
SDR-X	09418	X	10/box	50
SDR-Y	09419	Y	10/box	50
SDR-Z	09420	Z	10/box	50
SDR-L1	09400	L1	10/box	50
SDR-L2	09401	L2	10/box	50
SDR-L3	09402	L3	10/box	50
SDR-T1	09412	T1	10/box	50
SDR-T2	09413	T2	10/box	50
SDR-T3	09414	T3	10/box	50

Continued on next page

Specifications and Ordering Information for ScotchCode™ SDR Wire Marker Tape (refills) (continued)

Product Number	UPC (054007-)	Description	Inner Unit Pack	Case Qty.
SDR- + (Plus)	09421	—	10/box	50
SDR- - (Minus)	09422	—	10/box	50
SDR-BK	09423	Black	10/box	50
SDR-BL	09424	Blue	10/box	50
SDR-BN	09425	Brown	10/box	50
SDR-GN	09426	Green	10/box	50
SDR-GY	09427	Gray	10/box	50
SDR-MC	09404	Multiple Colors	10 rls/pk	50 rolls or 5 packs
SDR-OR	09428	Orange	10/box	50
SDR-RD	09429	Red	10/box	50
SDR-VL	09458	Violet	10/box	50
SDR-WH	09430	White	10/box	50
SDR-YL	09431	Yellow	10/box	50

Books

ScotchCode™ SPB Pre-Printed Wire Marker Books

When you need to mark wires quickly, try ScotchCode SPB Pre-printed Wire Marker Books. These handy books, 15 in all, contain printed vinyl-coated cloth wire and terminal markers with clearly printed letters, numbers and industry-standard legends. Books for alarm systems and load centers are also available. Each SPB book contains a minimum of 450 marks.

The cover of each SPB book lists the complete contents. On the back is a listing that helps you find the SPB book you need.

ScotchCode SWB Write-On Books

This self-laminating, write-on marker was designed for small volume applications involving special or complex legends that are handwritten at the job site.

ScotchCode SMP Marker Pens

3M ScotchCode SMP Permanent Marking Pens are suggested for use with ScotchCode write-on products. These pens perform well on nonporous surfaces, have an extra-fine point with permanent, quick-drying ink and are available in black ink. They have superior UV and water resistance.



52

Features — Advantages — Benefits

ScotchCode Wire Marker Books

Clearly printed (SPB-specific)	Legible, neat	Easy to use
Wide variety of printed characters	Contain marks for several standard applications	Increases productivity
Single character marker included with each marker for terminal block identification	Convenient	Easy to use



Product Referral Generator

Taping	pg. 1
Terminating	
– Terminals	pg. 35
Fastening	pg. 147
Connecting	
– Spring Connectors	pg. 22


Specifications and Ordering Information for ScotchCode™ SPB Pre-Printed Wire Marker Book

Product Number	UPC (054007-)	Quantity (each)	Contents	Inner Unit Pack	Minimum Order Case Qty.
SPB-01	49951	45 15	0-9 L1-L3, T1-T3	1/bag	5
SPB-02	49952	10	A-Z, 0-15, +, -, /	1/bag	5
SPB-03	49953	10	1-45	1/bag	5
SPB-04	49954	150	1, 2, 3	1/bag	5
SPB-05	49955	150	A, B, C	1/bag	5
SPB-06	49956	150	T1, T2, T3	1/bag	5
SPB-07	49957	150	L1, L2, L3	1/bag	5
SPB-08	49958	6 4 2	1-15 16-90 A-Z, +, -, /, 0	1/bag	5
SPB-09	49959	45 30	1, 2, 3, A, B, C L1-L3, T1-T3	1/bag	5
SPB-11	49960	15	1-30	1/bag	5
SPB-12	49961	15 8 6 21	A-Z + - Write-On Markers	1/bag	5
SPB-13	49962	45 33 27 21	+ , -, AC, DC POS, NEG, GND NEUT, SPARE Write-On Markers	1/bag	5
SPB-14	49963	10	46-90	1/bag	5
SPB-15AS1	49964	9 5 2 21	30 Alarm System Legends* 1-15 16-45 Write-On Markers	1/bag	5
SPB-16LC1	49965	5 110	68 Load Center Legends** Write-On Markers	1/bag	5

*30 Alarm System Legends: + Circuit +, - Circuit -, + DC, -DC, AC AC, ZONE 1, ZONE 2, ZONE 3, ZONE 4, ZONE 5, ZONE 6, ZONE 7, ZONE 8, ZONE 9, SHUNT, GROUND, FIRE, BA BA, FEED, RETURN, PHONE FEED, PHONE RETURN, BELL, ANNUNCIATOR, TAMPER, 12 VOLT, 16 VOLT, 24 VOLT, SMOKE DETECTOR, THERMOSTAT.

**68 Load Center Legends: MAIN, REFRIGERATOR, FREEZER, RANGE, DISPOSAL, COMPACTOR, DISHWASHER, KITCHEN LIGHTS, KITCHEN OUTLETS, GFI KITCHEN, LIVING LIGHTS 1, LIVING LIGHTS 2, LIVING OUTLETS 1, LIVING OUTLETS 2, DINING LIGHTS, DINING OUTLETS, DEN LIGHTS, DEN OUTLETS, BATH 1 GFI, BATH 1 OUTLETS, BATH 1 LIGHTS, BATH 2 GFI, BATH 2 OUTLETS, BATH 2 LIGHTS, BATH 3 GFI, BATH 3 OUTLETS, BATH 3 LIGHTS, BEDR'M 1 LIGHTS, BEDR'M 1 OUTLETS, BEDR'M 2 LIGHTS, BEDR'M 2 OUTLETS, BEDR'M 3 LIGHTS, BEDR'M 3 OUTLETS, BEDR'M 4 LIGHTS, BEDR'M 4 OUTLETS, BEDR'M 5 LIGHTS, BEDR'M 5 OUTLETS, REC LIGHTS, REC OUTLETS, PATIO LIGHTS, PATIO OUTLETS, HEATING 1, HEATING 2, AIR COND 1, AIR COND 2, WATER HEATER 1, WATER HEATER 2, WASHER, DRYER, OUTSIDE OUTLETS, ATTIC LIGHTS, ATTIC OUTLETS, BASEM'T LIGHTS, BASEM'T OUTLETS, UTILITY LIGHTS, UTILITY OUTLETS, DRIVEWAY LIGHTS, POOL GFI, POOL LIGHTS, POOL HEATING, SHED LIGHTS, SHED OUTLETS, ENTRY LIGHTS, ENTRY OUTLETS, GARAGE LIGHTS, GARAGE OUTLETS, SUNR'M LIGHTS, SUNR'M OUTLETS.

Specifications and Ordering Information for ScotchCode™ SWB Write-On Wire Marker Books

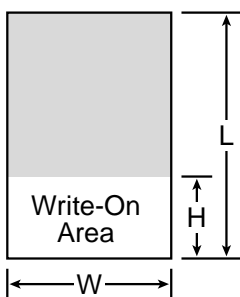

Product Number	UPC (054007-)	Labels per Book	Write-On Area		Marker Size		Recommended Wire O.D.	Inner Unit Pack	Min. Order Case Qty.
			W	H	W	L			
SWB-1	49904	180	0.5" (13 mm)	0.5" (13 mm)	0.5" (13 mm)	1.5" (28 mm)	0.16 x 0.31" (4 x 8 mm)	1/bag	5
SWB-2	49905	120	0.75" (19 mm)	0.75" (19 mm)	0.75" (19 mm)	1.75" (44 mm)	0.24 x 0.31" (6 x 8 mm)	1/bag	5
SWB-3	49906	60	1.0" (25 mm)	1.0" (25 mm)	1.0" (25 mm)	2.85" (72 mm)	0.32 x 0.58" (8 x 15 mm)	1/bag	5
SWB-4	49907	30	1.0" (25 mm)	1.0" (25 mm)	1.0" (25 mm)	5.0" (127 mm)	0.32 x 1.55" (8 x 39 mm)	1/bag	5

Specifications and Ordering Information for ScotchCode SMP Marker Pens

Product Number	UPC (054007-)	Ink Color	Inner Unit Pack	Case Qty.
SMP-B	09963	Black	10/box	50

Computerized Systems

ScotchCode™ SCS-ASW Software

Wire marker printing is no longer a time-consuming job thanks to the ScotchCode SCS-ASW Computer Sheet Software (version 2.0). Virtually any 3M adhesive style computer wire marker can be printed in a wide variety of sizes. You can also store multiple custom lists using our software. This product runs on most IBM and compatible personal computers, eliminating costly label-making machines. We added features that include on-line help screens, text import capability, single key field entry and a print preview/alignment feature for your convenience.

ScotchCode SCS-AM Adhesive Wire Marker Computer Sheets

3M ScotchCode SCS-AM Adhesive Wire Markers take advantage of electronic word processing to help you "custom" create your markers for all your applications. Each marker has a clear, self-laminating, wrap-around tail that protects the legend from oil, grease, water, chemicals and other foreign matter. SCS computer sheets are pin-fed, continuous sheets perforated to allow separation on individual rows of markers. The fan-folding provides easy fit in a shirt pocket. Markers are sold by the case.

ScotchCode STS Wire Marker Type-On Sheets

ScotchCode STS Wire Marker Type-On Sheets differ from the SCS computer sheets in their absence of tractor-feed holes and perforations between sheets. They are packaged to hand-feed into your typewriter, with 100 individual one-page sheets per case.



ScotchCode™ SCS-ASW Software and SCS-AM Computer Sheets



Product Referral Generator

Connecting	
– Spring Connectorspg. 22
Tapingpg. 1
Terminating	
– Terminalspg. 35
Fasteningpg. 147
Tubing	
– Heat Shrinkpg. 327



Features — Advantages — Benefits


ScotchCode SCS Wire Marker Computer Sheets

Markers are easy to apply	Creates efficiency in the field	Increases productivity
Wrap around application is excellent for marking round and flat cables	Able to apply in variety of locations	Saves time
Transparent legend overwrap protects print	Keeps mark legible	Improves quality
3M software provides user friendly marker design	Marks can be prepared prior to need in field	Increases productivity
Resists dirt, heat, oil and moisture	Keeps mark clear and dry	Improves quality
Fifteen sizes to choose from	Meets most application needs	Improves quality
Excellent for high volume applications	Computerized marking system creates efficiency	Increases productivity
Over-wrapped tail	Keeps text clear and legible	Improves quality

Specifications and Ordering Information for ScotchCode SCS-ASW Software

Product Number	UPC (054007-)	Description	Minimum Order Case Qty.
SCS-ASW 2.0	50191	Floppy Diskettes: 3.5, IBM and IBM Compatibles; File Size: 515K; Required RAM: 512K	1


Specifications and Ordering Information for ScotchCode™ SCS-AM Adhesive Wire Marker Sheets

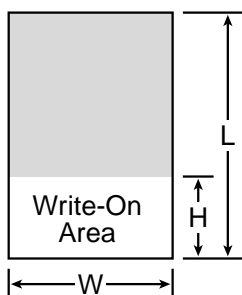

Product Number	UPC (054007-)	Write-On Area		Marker Size		Sheet Width	Markers per Row	Markers per Sheet	Sheets per Box	Min. Order Case Qty.
		W	H	W	L					
SCS-AM02*	49380	0.50" (12,70 mm)	0.38" (9,65 mm)	0.50" (12,70 mm)	0.75" (19,05 mm)	9.5" (241,30 mm)	14	168	30	5,000 markers
SCS-AM04	49381	0.50" (12,70 mm)	0.50" (12,70 mm)	0.50" (12,70 mm)	1.44" (36,58 mm)	9" (228,60 mm)	16	128	40	5,000 markers
SCS-AM06*	49382	0.75" (19,05 mm)	0.50" (12,70 mm)	0.75" (19,05 mm)	1.75" (44,45 mm)	9" (228,60 mm)	9	54	93	5,000 markers
SCS-AM08	49383	0.80" (20,32 mm)	0.50" (12,70 mm)	0.80" (20,32 mm)	1.44" (36,58 mm)	6.3" (160,02 mm)	6	48	105	5,000 markers
SCS-AM10	49384	1.00" (25,40 mm)	0.50" (12,70 mm)	1.00" (25,40 mm)	1.44" (36,58 mm)	9" (228,60 mm)	8	64	79	5,000 markers
SCS-AM12	49385	1.00" (25,40 mm)	0.75" (19,05 mm)	1.00" (25,40 mm)	2.25" (57,15 mm)	9" (228,60 mm)	8	32	157	5,000 markers
SCS-AM14	49386	1.00" (25,40 mm)	1.00" (25,40 mm)	1.00" (25,40 mm)	3.75" (92,25 mm)	9" (228,60 mm)	8	24	105	2,500 markers
SCS-AM16*	49387	1.00" (25,40 mm)	1.50" (38,10 mm)	1.00" (25,40 mm)	5.94" (150,88 mm)	9.5" (241,30 mm)	8	16	157	2,500 markers
SCS-AM18*	49388	1.00" (25,40 mm)	1.50" (38,10 mm)	1.00" (25,40 mm)	7.44" (188,98 mm)	9.5" (241,30 mm)	4	6	157	2,500 markers
SCS-AM20	49389	1.90" (48,26 mm)	0.75" (19,05 mm)	1.90" (48,26 mm)	3.19" (81,03 mm)	9" (228,60 mm)	4	12	209	2,500 markers
SCS-AM22	49390	2.00" (50,80 mm)	0.50" (12,70 mm)	2.00" (50,80 mm)	1.44" (36,58 mm)	9" (228,60 mm)	4	32	157	5,000 markers
SCS-AM24	49391	2.00" (50,80 mm)	0.75" (19,05 mm)	2.00" (50,80 mm)	2.25" (57,15 mm)	9" (228,60 mm)	4	16	157	2,500 markers
SCS-AM26	49392	2.00" (50,80 mm)	1.00" (25,40 mm)	2.00" (50,80 mm)	3.75" (92,25 mm)	9" (228,60 mm)	4	12	209	2,500 markers
SCS-AM28	49393	2.00" (50,80 mm)	1.50" (38,10 mm)	2.00" (50,80 mm)	5.94" (150,88 mm)	9" (228,60 mm)	4	8	313	2,500 markers
SCS-AM30*	49394	2.00" (50,80 mm)	1.50" (38,10 mm)	2.00" (50,80 mm)	7.44" (188,98 mm)	9.5" (241,30 mm)	4	8	313	2,500 markers

*Denotes product numbers that must be printed on a wide-carriage printer.

Specifications and Ordering Information for ScotchCode STS Wire Marker Type-On Sheets

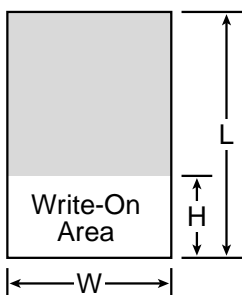

Product Number	UPC (054007-)	Write-On Area		Marker Size		Sheet Width	Markers per Row	Markers per Sheet	Minimum Order Case Qty.
		W	H	W	L				
STS	12317	0.75" (19 mm)	0.3125" (8 mm)	0.75" (19 mm)	1.375" (35 mm)	8.5" (215,90 mm)	11	55	100 sheets

Important Notice

All statements, technical information, and recommendations related to 3M's products are based on information believed to be reliable, but the accuracy or completeness is not guaranteed. Before using this product, you must evaluate it and determine if it is suitable for your intended application. You must assume all risks and liability associated with such use. Any statements related to the product which are not contained in the 3M's current publications, or any contrary statements contained on your purchase order shall have no force or effect unless expressly agreed upon, in writing, by an authorized officer of 3M.

Warranty; Limited Remedy; Limited Liability.

3M's product warranty is stated in its Product Literature available upon request. **3M MAKES NO OTHER WARRANTIES INCLUDING, BUT NOT LIMITED TO, ANY IMPLIED WARRANTY OF MERCHANTABILITY OR FITNESS FOR A PARTICULAR PURPOSE.**

If this product is defective within the warranty period stated in the product literature, your exclusive remedy shall be, at 3M's option, to replace or repair the 3M product or refund the purchase price of the 3M product. **Except where prohibited by law, 3M will not be liable for any loss or damage arising from this 3M product, whether direct, indirect, special, incidental or consequential regardless of the legal theory asserted.**